


Data sheet

7788.2 SSOIF 16+

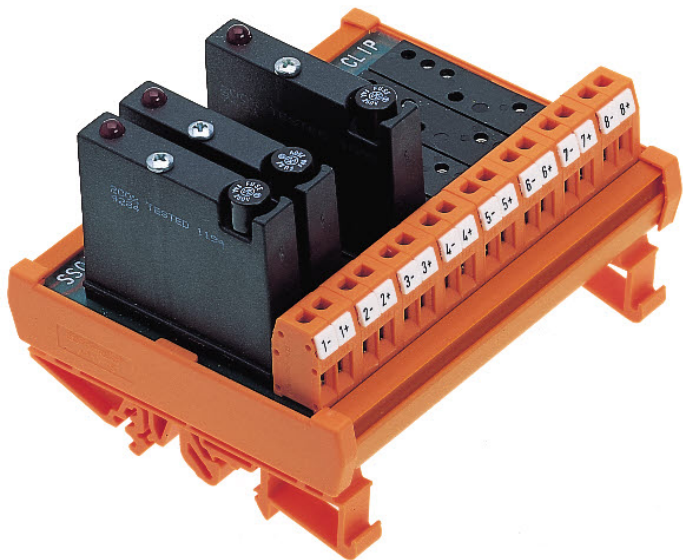

Multiple solid-state output modules for G4 SSR relays, Screw connection, Mounting type: Mounting rail TS 35, 16 channels, Positive switching, Delivered without SSR relay

Business data

Article number	7788.2
Article name	SSOIF 16+
GTIN (EAN)	4044211078065
Packaging unit	1
Quantity unit	PC
Weight per piece (not including packaging)	269.9 g
Weight per piece (including packaging)	375.3 g
Unit of weight	G
Customs number	85365003
Country of origin	NL
Product description	Solid-state output module

Data sheet

7788.2 SSOIF 16+

Technical data

Dimensions

Length	87 mm
Width	212 mm
Height	57 mm

Ratings

Overvoltage category	III
Contamination degree	2

Connection data

Connection principle	Screw connection
Wire cross-section single core (rigid), min.	0.2 mm ²
Wire cross-section single-core (rigid), max.	4 mm ²
Wire cross-section stranded, min.	0.2 mm ²
Wire cross-section stranded, max.	2.5 mm ²
Wire cross-section stranded with wire-end ferrules, min.	0.2 mm ²
Wire cross-section stranded with wire-end ferrules, max.	2.5 mm ²
Stripping length	7 mm
Torque	0.6 Nm

Input data

Number of channels	16
--------------------	----

Materials

Working temperature, min.	-20 °C
Working temperature, max.	55 °C

Further technical data

Remarks	+ schaltend
Test voltage	4 kV

Environmental Product Compliance

REACH Conform	yes
REACH Reference date	2024-01-23
REACH Candidate Substance Note	No
RoHS Conform	yes

Approvals



Standards and regulations

Standards / specifications	DIN VDE 0110 / EN 50178
----------------------------	-------------------------

Data sheet

7788.2 SSOIF 16+

Media

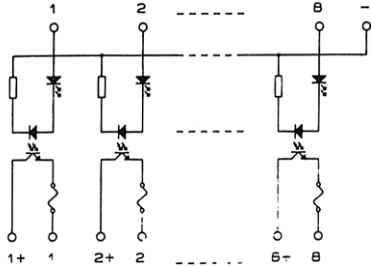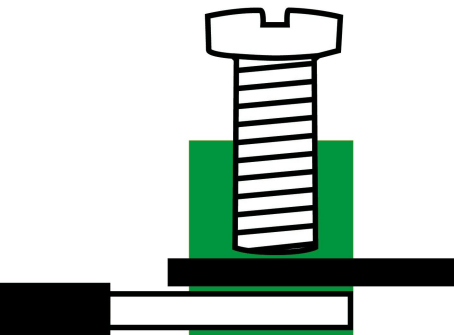

Accessories
