

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2041020409

Status:


Active

Overview:

VersaBlade Wire-to-Wire Connector System

Description:

Wire-to-Wire VersaBlade Hybrid Plug Housing, 4 Circuits, Friction Lock, Glow-Wire Capable

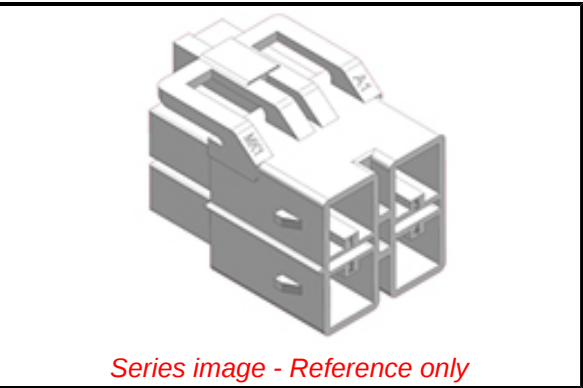

Documents:

Drawing (PDF)

Product Specification 2041020609-000 (PDF)

Packaging Specification 2041020609-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	204102
Application	Power, Wire-to-Wire
Overview	VersaBlade Wire-to-Wire Connector System
Product Name	VersaBlade
UPC	191128287784
Physical	
Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester Alloy
Net Weight	3.356/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	8.00mm, 8.50mm
Pitch - Termination Interface	8.00mm, 8.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +110°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	2041020609-001
Product Specification	2041020609-000
Sales Drawing	2041020409-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

204102 Series

Mates With

VersaBlade Plug Housing 204102-0609

Use With

VersaBlade Crimp Terminals 35745 , 35746

 TPA 35965 , 104081

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION