


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190980073](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Snap Spade Tap for 12-10 AWG Wire, Stud Size 8 (M4), Loose Piece in Box

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19098
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	Krimptite
Type	Spade Snap
UPC	800755081589
Physical	
Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	1.213/g
Packaging Type	Carton
Stud Size	8 (M4)
Wire Size AWG	10, 12
Wire Size mm²	0.25-1.50
Material Info	
Engineering Number	C-1718-08
Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	CCD10503

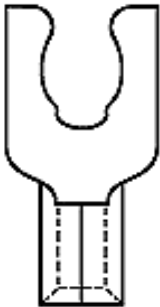

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS Green Image Not Relevant Not Contained

Search Parts in this Series
[19098](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION