

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190570054

Status:

Active

Overview:

Solderless Terminals

Description:

AviKrimp Ring Tongue Terminal for 14-16 AWG Wire, Nylon, Stud Size 6

Documents:

Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification 194130105-000 (PDF)

Product Specification PS-19902-013-001 (PDF)

Product Specification 194130106-000 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19057
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	Avikrimp
Type	Ring
UPC	800753058279

Physical

Barrel Type	Closed
Color - Resin	Blue
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Net Weight	1.098/g
Packaging Type	Carton
Stud Size	6 (M3.5)
Temperature Range - Operating	105°C
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.32mm max.
Wire Size AWG	14, 16
Wire Size mm²	1.00-2.50

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	B-523-06
--------------------	----------

Reference - Drawing Numbers

Product Specification	194130105-000, 194130106-000, PS-19902-011-001, PS-19902-013-001
Sales Drawing	BCD50101

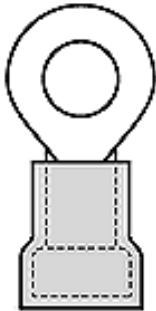

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
19057 Series