


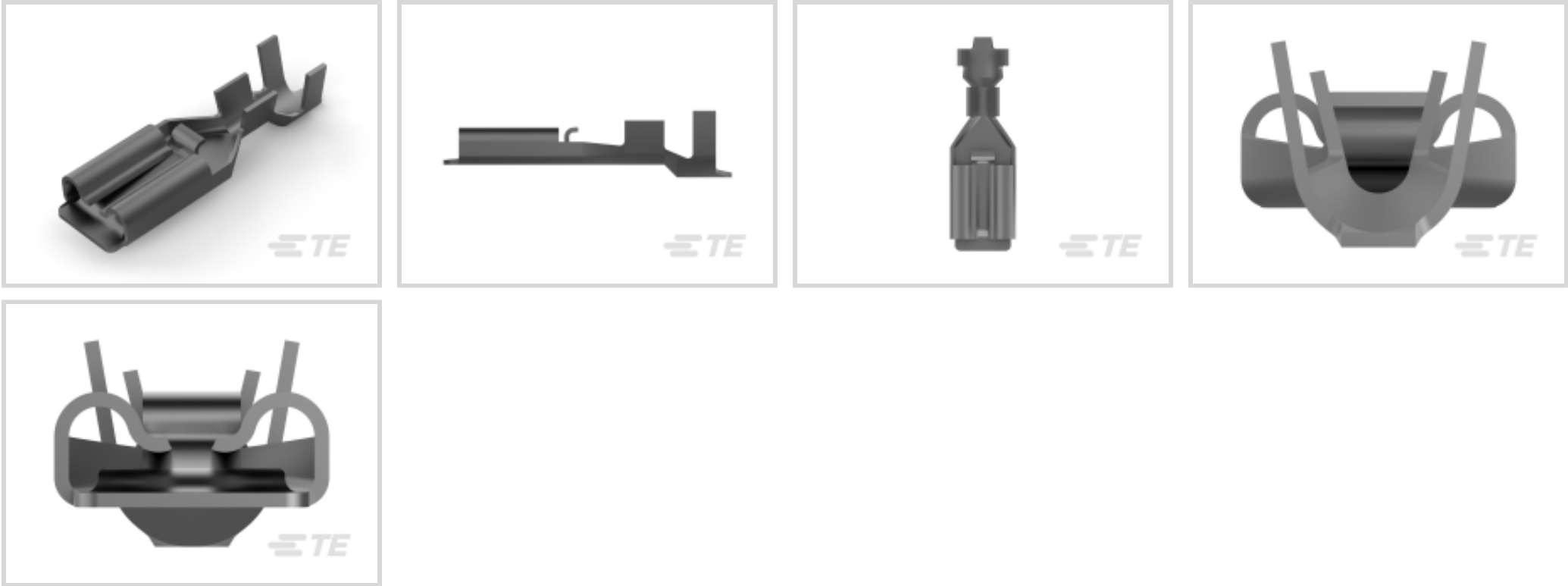

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUL 2021 (219) Candidate List Declared Against: JAN 2021 (211) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts






TE Part # 2-2150570-2
OC-PA-E-FA-080F140F-001-0049



TE Part # 2150570-2
OC-AT-E-FA-080F140F-001-0049

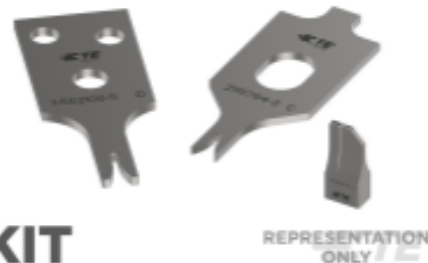

KIT
TE Part # 7-2150570-7
OCEAN-080F140F-CRIMPTOOLINGKIT


Customers Also Bought



TE Part #2-2232043-2
2P, RAST 5 Tab Header, THV



TE Part #7-2150008-7
OCEAN_2.0_SPARE_PART_KIT-130F180F

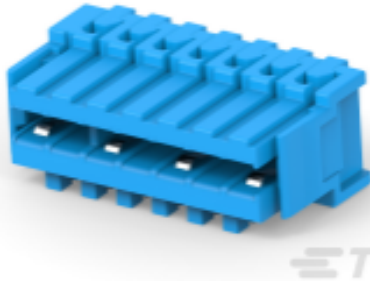

TE Part #1-284866-7
Direct mount card edge conn.,




TE Part #1-368587-1
PDL 4P CAP 3.96 D/R F/H(GWT) N



TE Part #1534077-3
MULTIFIT MK2ASSY 3P,IR



TE Part #176498-2
PL MKII 187 REC HSG 2P NYLON BLACK

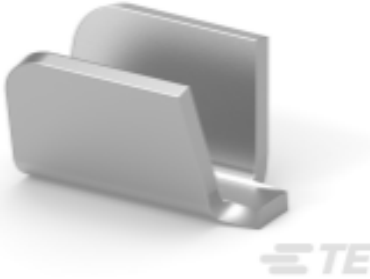

TE Part #1-62306-4
AMVAR SPLC 1500-5000 020TPBR

TE Part #1649222-4
OJE-SH-112DM,801

Documents

Product Drawings

PL 187 REC 20-18 AWG 0.30 X 38.6 PTBR

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_173724-7_W.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_173724-7_W.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_173724-7_W.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.



Product Specifications

Application Specification

English

Product Environmental Compliance

TE Material Declaration

English

Instruction Sheets

Instruction Sheet (non U.S.)

English

POSITIVE LOCK EX CONTACT

English