

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing



1424364

<https://www.phoenixcontact.com/us/products/1424364>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Box mounting bases D15, with single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 2, lateral, 2x M20, height: 52 mm, cable gland: none, Standard

Commercial data

Item number	1424364
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF56
Product key	BF7APE
Catalog page	Page 527 (C-2-2019)
GTIN	4055626371061
Weight per piece (including packing)	173.2 g
Weight per piece (excluding packing)	169.6 g
Customs tariff number	85389099
Country of origin	CN

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing



1424364


<https://www.phoenixcontact.com/us/products/1424364>

Technical data

Product properties

Product type	Housing with locking latch
Housing type	Box mounting bases
Product family	HC-STA-D
Application	Standard
Type	D15
No. of cable outlets	2
Type of the screw connection	2x M20
Cable outlet	lateral
Pg screw connection	none

Dimensions

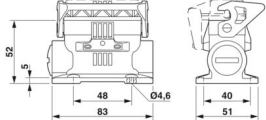Dimensional drawing	
Width	51 mm
Height	52 mm
Length	80 mm
Hole diameter	4.5 mm

Material specifications

Flammability rating according to UL 94	V0 (Interlock)
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated
Locking latch material	PA

Mechanical properties

Mechanical data

Type of the screw connection	2x M20
Locking type	Latch

Connection data

Tightening torque	0.8 Nm ... 1.2 Nm (for M4 mounting screws on the surface-mount housing)
-------------------	---

Mounting

Assembly note	One opening is sealed with a plastic filler plug and can be opened using a screwdriver.
---------------	---

Environmental and real-life conditions

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing



1424364

<https://www.phoenixcontact.com/us/products/1424364>

Ambient conditions

Degree of protection	IP66
	IP67
Impact strength	IK08
Ambient temperature (operation)	-40 °C ... 125 °C

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing




1424364

<https://www.phoenixcontact.com/us/products/1424364>

Drawings

Dimensional drawing

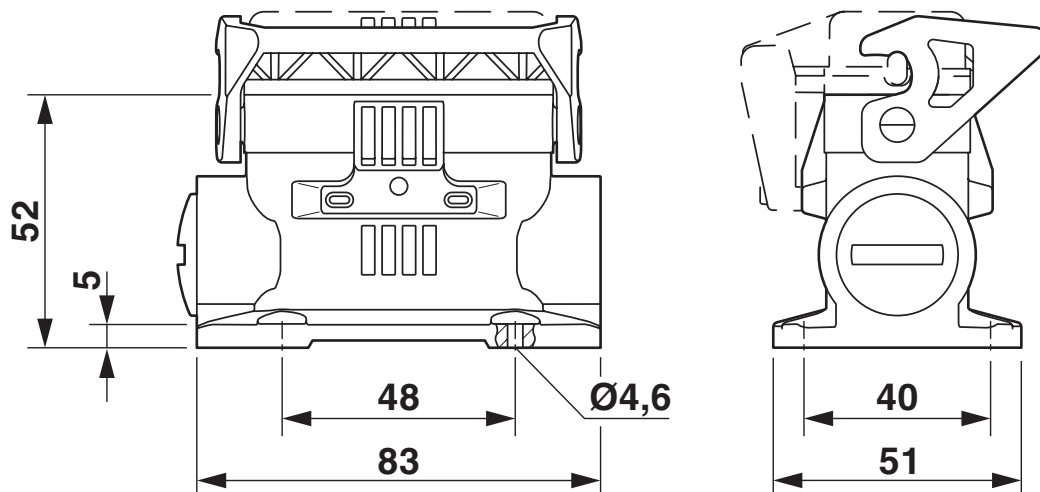

Dimensional drawing

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1424364>

**DNV**
Approval ID: TAE000037S

**cUL Recognized**
Approval ID: E255026

**UL Recognized**
Approval ID: E255026

**EAC**
Approval ID: RU C-DE.BL08.B.00511

cULus Recognized

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing



1424364

<https://www.phoenixcontact.com/us/products/1424364>

Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing



1424364

<https://www.phoenixcontact.com/us/products/1424364>

Accessories

G-INS-M20-S68N-NNES-S - Cable gland

1411163

<https://www.phoenixcontact.com/us/products/1411163>



Cable gland, material for screw connection: Brass, nickel-plated, application: Standard, external cable diameter 6 mm ... 12 mm, shielding: no, connecting thread: M20 x 1.5, color: silver, with O-ring

G-INSEC-M20-S68N-NCRS-S - Cable gland

1411189

<https://www.phoenixcontact.com/us/products/1411189>



Cable gland, material for screw connection: Brass, nickel-plated, application: EMC, external cable diameter 9 mm ... 13 mm, shielding: yes, connecting thread: M20 x 1.5, color: silver, with O-ring

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing

1424364

<https://www.phoenixcontact.com/us/products/1424364>



G-INS-M20-M68N-SNES-S - Cable gland

1424543

<https://www.phoenixcontact.com/us/products/1424543>



Cable gland, material for screw connection: Stainless steel 1.4305, application: Standard, external cable diameter 6 mm ... 12 mm, shielding: no, connecting thread: M20 x 1.5, color: silver, with O-ring

A-INSP-M20-65N-P-BK - Screw plug

1415206

<https://www.phoenixcontact.com/us/products/1415206>



Screw plug, material for screw connection: PA, connecting thread: M20 x 1.5, color: jet black RAL 9005, with O-ring

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing

1424364

<https://www.phoenixcontact.com/us/products/1424364>



HC-M-BS-M20 - Screw plug

1645846

<https://www.phoenixcontact.com/us/products/1645846>

Screw plug, material for screw connection: Brass, nickel-plated, connecting thread: M20 x 1.5, color: silver



HC-M-D15-MF-HB - Module carrier frame

1062122

<https://www.phoenixcontact.com/us/products/1062122>

Module carrier frame, size: D15, 0.14 mm² ... 2.5 mm², application: Module carrier frame, for size D15 housings



HC-STA-D15-SLWS-2SSM20-EL-AL - Housing

1424364

<https://www.phoenixcontact.com/us/products/1424364>



HC-D15-BC-HI-PLBK - Protective cover

1414673

<https://www.phoenixcontact.com/us/products/1414673>

Protective cover D15, for single locking latch, protective cover material: PC, height: 15.2 mm, seal: no



HC-D15-BCFS-PR-BK - Protective cover

1346518

<https://www.phoenixcontact.com/us/products/1346518>

Protective cover D15, for single locking latch, protective cover material: PC, height: 19 mm, seal: yes



HC-STA-D15-SLWS-2SSM20-EL-AL - Housing

1424364

<https://www.phoenixcontact.com/us/products/1424364>



HC-D15-SL-PLBK - Housing brackets

1414667

<https://www.phoenixcontact.com/us/products/1414667>



Replacement single locking latch, plastic, for HC-EVO-D15....BK and HC-STA-D15....AL housings

WP-G HF IP66 M20 BK - Screw connection

3240898

<https://www.phoenixcontact.com/us/products/3240898>



Cable gland, metric thread, IP66 protection, straight

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing

1424364

<https://www.phoenixcontact.com/us/products/1424364>



WP-G HF IP69K M20 BK - Screw connection

3240884

<https://www.phoenixcontact.com/us/products/3240884>



Cable gland, metric thread, IP68/69k protection, straight

WP-GA HF IP66 M20 BK - Screw connection

3240926

<https://www.phoenixcontact.com/us/products/3240926>



Cable gland, metric thread, IP66 protection, angled

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing

1424364

<https://www.phoenixcontact.com/us/products/1424364>



WP-GA HF IP69K M20 BK - Screw connection

3240912

<https://www.phoenixcontact.com/us/products/3240912>

Cable gland, metric thread, IP68/69k protection, angled



WP-GR HF IP66 M20 BK - Screw connection

3240954

<https://www.phoenixcontact.com/us/products/3240954>

Cable gland, metric thread, IP66 protection, with strain relief



HC-STA-D15-SLWS-2SSM20-EL-AL - Housing

1424364

<https://www.phoenixcontact.com/us/products/1424364>



WP-GR HF IP69K M20 BK - Screw connection

3240940

<https://www.phoenixcontact.com/us/products/3240940>



Cable gland, metric thread, IP68/69k protection, with strain relief

WP-G PP HF M20 - Screw connection

3240998

<https://www.phoenixcontact.com/us/products/3240998>



Cable gland made from PP with metric thread, IP65 protection

HC-STA-D15-SLWS-2SSM20-EL-AL - Housing



1424364

<https://www.phoenixcontact.com/us/products/1424364>

WP-GT PP HF M20 - Screw connection

3241012

<https://www.phoenixcontact.com/us/products/3241012>

Cable gland made from PP with metric thread, rotatable, IP54 protection



WP-G BRASS IP40 M20 - Screw connection

3241047

<https://www.phoenixcontact.com/us/products/3241047>

Cable gland made from brass with metric thread, IP40 protection



HC-STA-D15-SLWS-2SSM20-EL-AL - Housing



1424364

<https://www.phoenixcontact.com/us/products/1424364>

WP-GT BRASS M20 - Screw connection

3241033

<https://www.phoenixcontact.com/us/products/3241033>

Cable gland made from brass with metric thread, rotatable, IP40 protection



WP-G BRASS IP65 M20 - Screw connection

3241061

<https://www.phoenixcontact.com/us/products/3241061>

Cable gland made from brass with metric thread, IP65 protection



Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com