



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

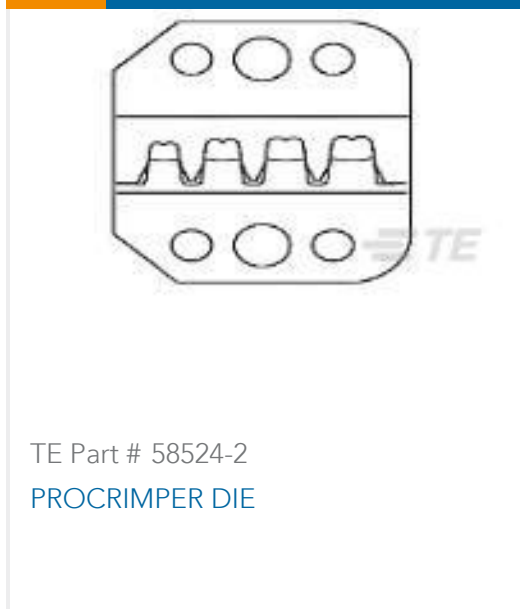
EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2024 (240) Candidate List Declared Against: JAN 2024 (240) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

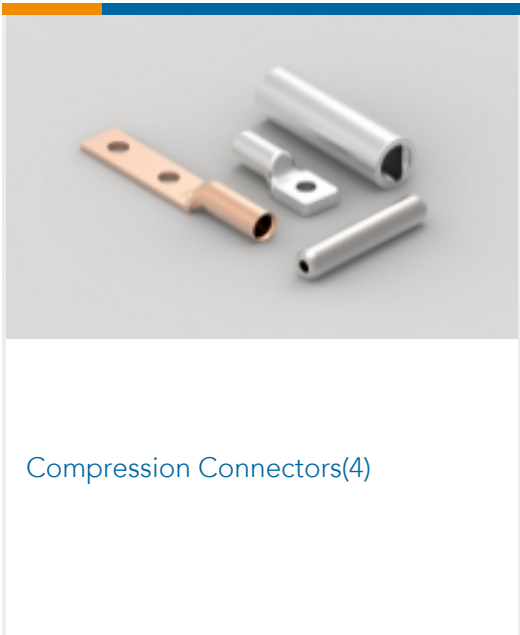
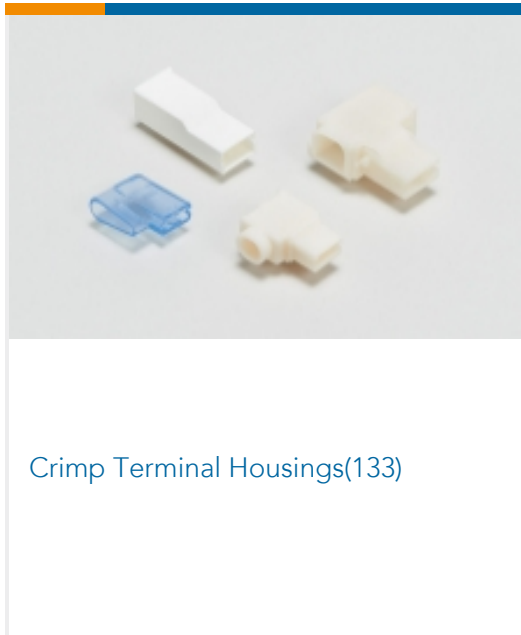
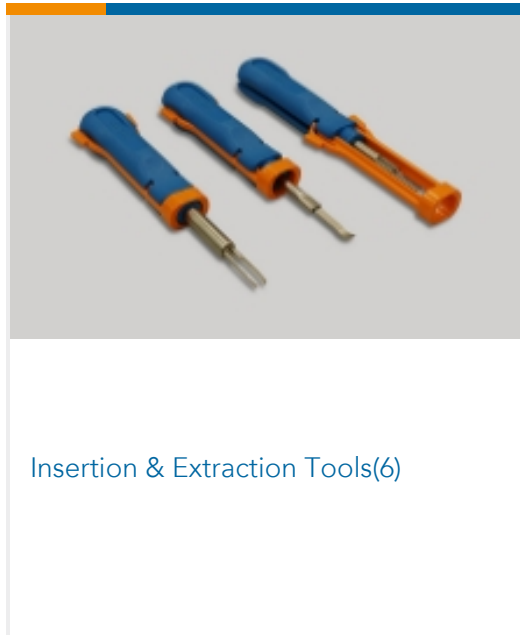
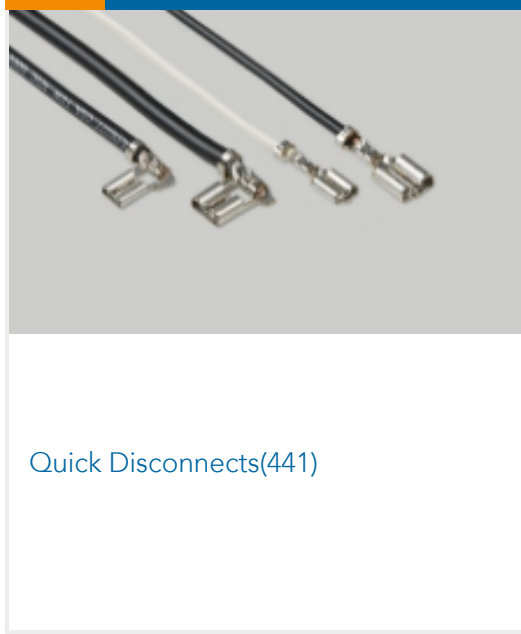
Compatible Parts



 TE Part # 2232112-1 250 FASTON,REC.,18-14 AWG,TPBR	 TE Part # 58524-1 PROCrimper TOOL & DIE	 TE Part # 90165-1 DAHT 250 FASTON REC 18-14 ASSY	 TE Part # 2232247-1 250 FASTON,REC.,16-10 AWG,BR
 TE Part # 1-280079-2 250 FASTON,REC.,14-17AWG,TPBR	 TE Part # 42845-2 250 FASTON REC 18-14 AWG TPBR	 TE Part # 58524-2 PROCrimper DIE	 TE Part # 2150016-1 OCEAN_2.0_Applicator-E-100F180F-REM
 TE Part # 2150016-2 OCEAN_2.0_Applicator-E-100F180F-REA	 TE Part # 7-2150016-7 OCEAN_2.0_SPARE_PART_KIT-100F180F		

Also in the Series

FASTON 250

 Compression Connectors(4)	 Crimp Terminal Housings(133)	 Insertion & Extraction Tools(6)	 Magnet Wire Terminals(1)
 PCB Terminals(134)	 Quick Disconnects(441)	 Splices(4)	

Customers Also Bought





TE Part # HDP26-24-31SE-L015
DEUTSCH HDP20 Housings



TE Part # DT06-4S-EP06
PLG, 4P, BLK, N, SEAL RET, CAP



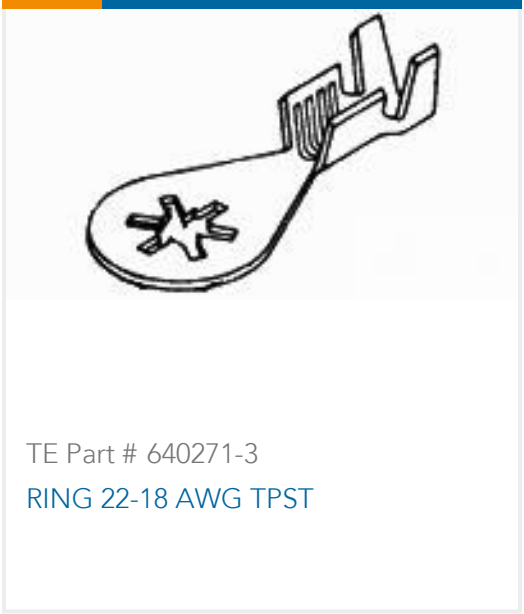
TE Part # 640417-2
BLADE REC 250 18-14AWG TPBR



TE Part # 640416-2
BLADE TAB 250 18-14AWG TPBR



TE Part # 62016-2
187 FASTON REC 18-14 AWG TPBR



TE Part # 640271-3
RING 22-18 AWG TPST



TE Part # 929941-3
JPT REC 2.8 Contact SWS Sn



TE Part # 114008-ZZ
EXT TOOL, SIZE 8, 8-10 AWG, N, GRN



TE Part # 1393315-9
V23132B2002A200=HCR

Documents

Product Drawings

250 FASTON FLAG REC 18-14 AWG TPBR

English

CAD Files

Customer View Model

ENG_CVM_CVM_60650-2_N.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_60650-2_N.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_60650-2_N.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.

Datasheets & Catalog Pages



82004 FASTON Terminals (Insulated and Uninsulated) Catalog - FASTON Receptacles Section

English

Product Specifications
Application Specification

English

Agency Approvals
UL Report

English