

CK2,5-ED-3,00BU AG - Crimp contact



1663695

<https://www.phoenixcontact.com/us/products/1663695>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Crimp contact, contact diameter: 2.5 mm, turned, Socket, contact material: Copper alloy, contact surface: silver-plated, connection cross section: 3 mm² ... 3 mm², AWG 12

Commercial data

Item number	1663695
Packing unit	100 pc
Minimum order quantity	100 pc
Sales key	BF65
Product key	BF7AID
Catalog page	Page 509 (C-2-2019)
GTIN	4017918123505
Weight per piece (including packing)	1.57 g
Weight per piece (excluding packing)	1.57 g
Customs tariff number	85366990
Country of origin	DE

CK2,5-ED-3,00BU AG - Crimp contact

1663695

<https://www.phoenixcontact.com/us/products/1663695>



Technical data

Notes

General	for HC-M-06..., HC-M-HV-, HC-M-08-, HC-M-20-, HC-A..., HC-B.., HC-BB..., HC-BBB..., and HC-HV contact carriers
---------	--

Mounting

Assembly note	The quality of a crimp connection is determined by DIN EN 60352-2.
---------------	--

Product properties

Product type	Crimp contact
Series	HC-M-06
	HC-M-HV
	HC-M-08
	HC-A
	HC-BB
	HC-B
	HC-HV
Type	Individual female contact
Contact material type	turned

 
Connection data

Connection method	Crimp connection
Contact connection type	Socket
Connection technology	Crimp connection
Conductor cross section	3 mm² ... 3 mm²
Connection cross section AWG	12
Stripping length of the individual wire	7.5 mm (9.5 mm at HC-M-HV...)
Conductor cross section flexible	3 mm² ... 3 mm²

Material specifications

Contact material	Copper alloy
Contact surface material	silver-plated

Dimensions

Dimensional drawing	
Width	4.5 mm
Height	4.5 mm
Depth	22.3 mm

Mechanical characteristics

CK2,5-ED-3,00BU AG - Crimp contact



1663695

<https://www.phoenixcontact.com/us/products/1663695>

Contact diameter	2.5 mm
------------------	--------

Mechanical properties

Mechanical data	
Insertion/withdrawal cycles	≥ 500

Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-40 °C ... 125 °C

CK2,5-ED-3,00BU AG - Crimp contact


1663695

<https://www.phoenixcontact.com/us/products/1663695>



Drawings

Dimensional drawing

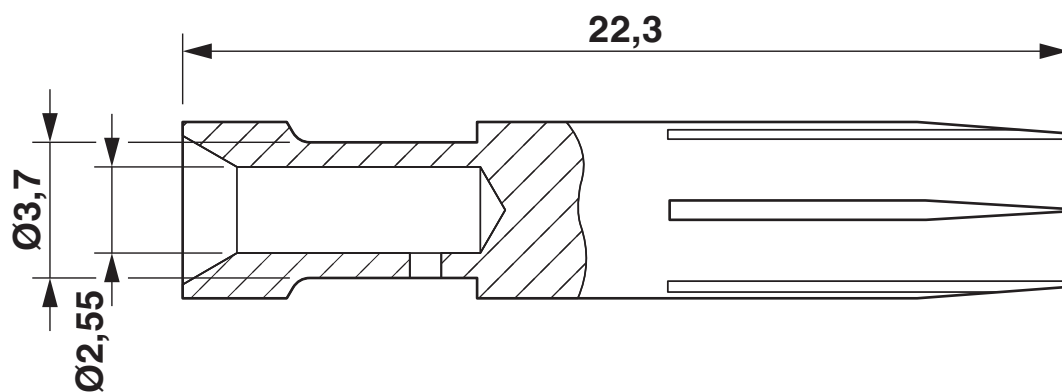

Dimensional drawing

CK2,5-ED-3,00BU AG - Crimp contact

1663695

<https://www.phoenixcontact.com/us/products/1663695>



Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1663695>



EAC

Approval ID: RU C-DE.AI30.B.01102

CK2,5-ED-3,00BU AG - Crimp contact



1663695

<https://www.phoenixcontact.com/us/products/1663695>

Classifications

ECLASS

ECLASS-11.0	27440204
ECLASS-12.0	27440204
ECLASS-13.0	27440204

ETIM

ETIM 9.0	EC000796
----------	----------

UNSPSC

UNSPSC 21.0	39121500
-------------	----------

CK2,5-ED-3,00BU AG - Crimp contact



1663695

<https://www.phoenixcontact.com/us/products/1663695>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

CK2,5-ED-3,00BU AG - Crimp contact

1663695

<https://www.phoenixcontact.com/us/products/1663695>



Accessories

CK2,5-ED-3,00ST AG - Crimp contact

1663624

<https://www.phoenixcontact.com/us/products/1663624>



Crimp contact, contact diameter: 2.5 mm, turned, Pin, contact material: Copper alloy, contact surface: silver-plated, connection cross section: 3 mm² ... 3 mm², AWG 12

CRIMPFOX-TC MP-6 - Crimping pliers with digital display

1202888

<https://www.phoenixcontact.com/us/products/1202888>



Crimping tool, for turned contacts, universal cross-section setting, up to a maximum of 6.0 mm², digital display with 0.01 mm increments, pressure lock can be unlocked, positioning tool necessary as an accessory for contact positioning

CK2,5-ED-3,00BU AG - Crimp contact

1663695

<https://www.phoenixcontact.com/us/products/1663695>



CRIMPFOX-TC HC 4 - Crimping pliers

1297083

<https://www.phoenixcontact.com/us/products/1297083>



Crimping pliers, for CK 1,6-ED..., CK 2,5-ED..., CK 4,0-ED... turned contacts, 4 marked die stations, unlockable pressure lock, lateral entry, incl. positioning tool

UNIFOX RT-CK 2.5 - Contact removal tool

1072067

<https://www.phoenixcontact.com/us/products/1072067>



Contact removal tool, for turned CK 2,5... contacts

CK2,5-ED-3,00BU AG - Crimp contact

1663695

<https://www.phoenixcontact.com/us/products/1663695>



UNIFOX MT-CK 1.6/2.5 - Assembly tool

1089092

<https://www.phoenixcontact.com/us/products/1089092>


Assembly tool, for CK 1.6... crimp contacts for small conductor cross sections



CF 500/DIE TC HC 4 - Crimp insert

1324132

<https://www.phoenixcontact.com/us/products/1324132>

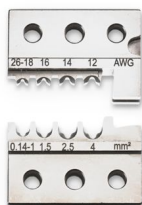

Die for CF 500 automatic crimping device, CK 1,6-ED..., CK 2,5-ED..., CK 4,0-ED... turned contacts, 4 marked die stations

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com