

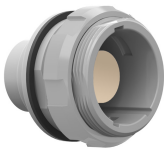
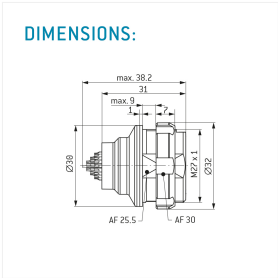


General information

Part number	GXBMFG-P22LFG0-0001
Termination	solder
Size	3,5
Locking principle	push
Coding	f_key_medi

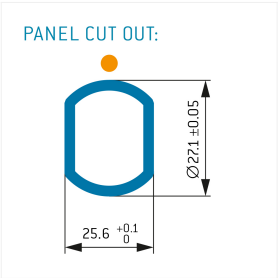

Illustrations may differ from original product.
Dimensions, unless otherwise specified, in mm.

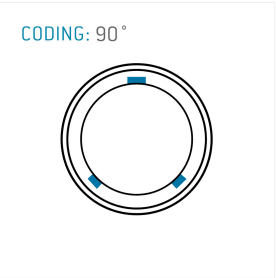

The pin layout corresponds to the view on the termination area

Contact insert description

Number of contacts	22
Contact type	sockets
Contact diameter	07mm
Insulator material	peek
Wire cross section	22_awg
Termination	solder
Termination diameter	085mm

Technical information

Max. creepage and air clearance distance	07_mm	iec_60601_2mopp_2moop
Nominal current single contact	075_a	iec_60512_5_2
Nominal current insert	3.375 A	vde_0298_4
Test voltage	11_kv_ac	eia_364_20f

safety text
iec_60601_receptacle

Mechanical and environmental data

Degree of protection*	ip68
Operating temperature	50_120_c
Mating cycles	5000

mated_unmated

Insulator materials MEDI-SNAP®

pei_peek_size_b_o_a

Material and surface treatments

Housing	pei_gray
Color option	gray
Contact	cu_alloy_gold

safety_text_2
data_text
ul_text
illustrative_text