

1526253

<https://www.phoenixcontact.com/us/products/1526253>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Y distributor, 5-position, Socket straight M12, coding: A, on Socket straight M12, coding: A and Plug straight M12, coding: A, Parallel distributor

Commercial data

Item number	1526253
Packing unit	5 pc
Minimum order quantity	5 pc
Sales key	BF10
Product key	BF1GAB
GTIN	4017918954291
Weight per piece (including packing)	28.84 g
Weight per piece (excluding packing)	26.25 g
Customs tariff number	85366990
Country of origin	PL

SAC-5P-M12YF/M12FS-M12MS VP - Y distributor



1526253

<https://www.phoenixcontact.com/us/products/1526253>

Technical data

Product properties

Product type	Y-distributor
Number of positions	5
No. of cable outlets	2
Shielded	no
Coding	A
Thread type	M12

Insulation characteristics

Overvoltage category	II
Degree of pollution	3


Electrical properties

Insulation resistance	$\geq 100 \text{ M}\Omega$
Nominal voltage U_N	48 V AC
	60 V DC
Nominal current I_N	4 A

Signaling

Status display	No
Status display present	No

Dimensions

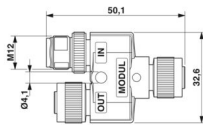Dimensional drawing	
Length	50.1 mm
Center distance	18 mm

Material specifications

Flammability rating according to UL 94	HB
Seal material	NBR
Material of grip body	TPU, hardly inflammable, self-extinguishing
Contact material	CuZn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Material for screw connection	Zinc die-cast, nickel-plated

Connector

Connection 1

SAC-5P-M12YF/M12FS-M12MS VP - Y distributor



1526253

<https://www.phoenixcontact.com/us/products/1526253>

Type	Socket straight M12
Coding type	A

Connection 2

Type	Socket straight M12
Coding type	A

Connection 3

Type	Plug straight M12
Coding type	A

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 100
-----------------------------	-------

Environmental and real-life conditions

Ambient conditions


Degree of protection	IP65
	IP67
Ambient temperature (operation)	-25 °C ... 90 °C (Plug / socket)

Standards and regulations

Standard designation	M12 connector
Standards/specifications	IEC 61076-2-101


Drawings

Dimensional drawing

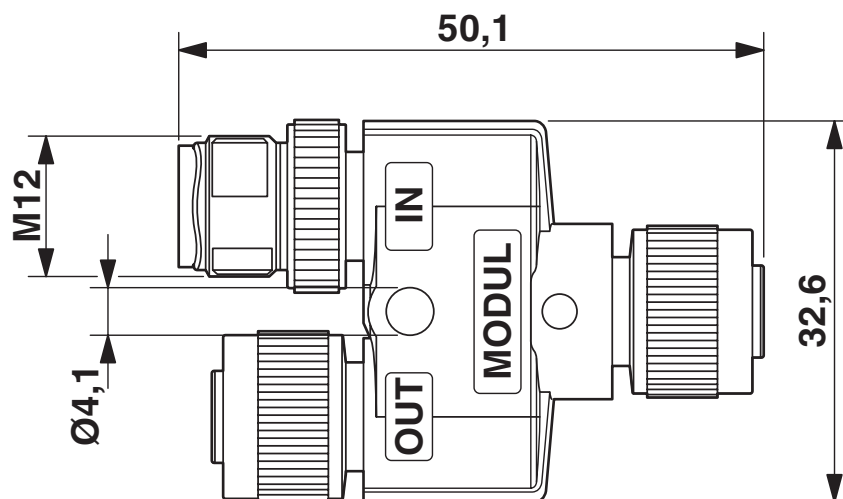

Plug M12 x 1, Y distributor

Schematic diagram

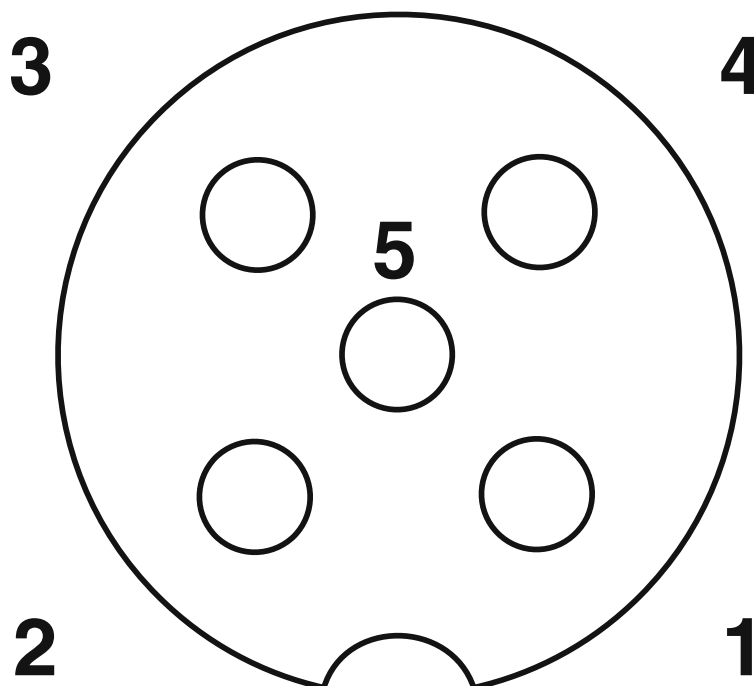

Pin assignment M12 socket, 5-pos., A-coded, socket side view


SAC-5P-M12YF/M12FS-M12MS VP - Y distributor



1526253


<https://www.phoenixcontact.com/us/products/1526253>

Schematic diagram

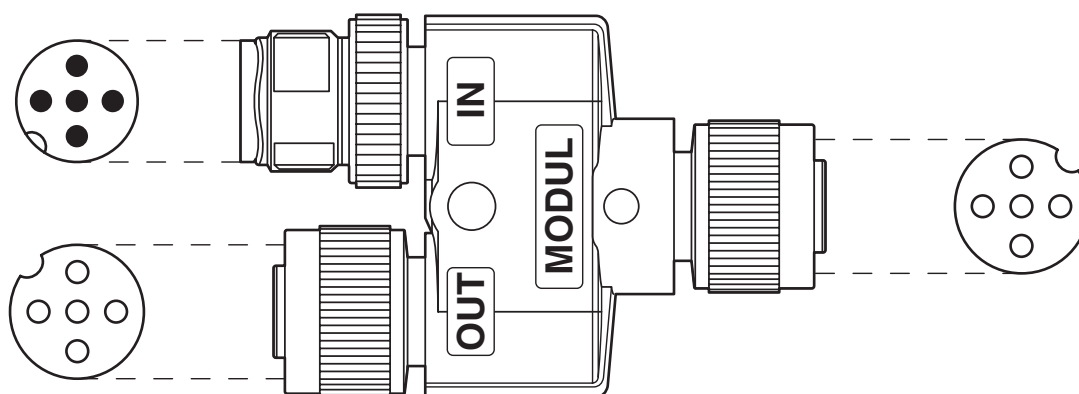

Layout of connector pin assignments

Schematic diagram

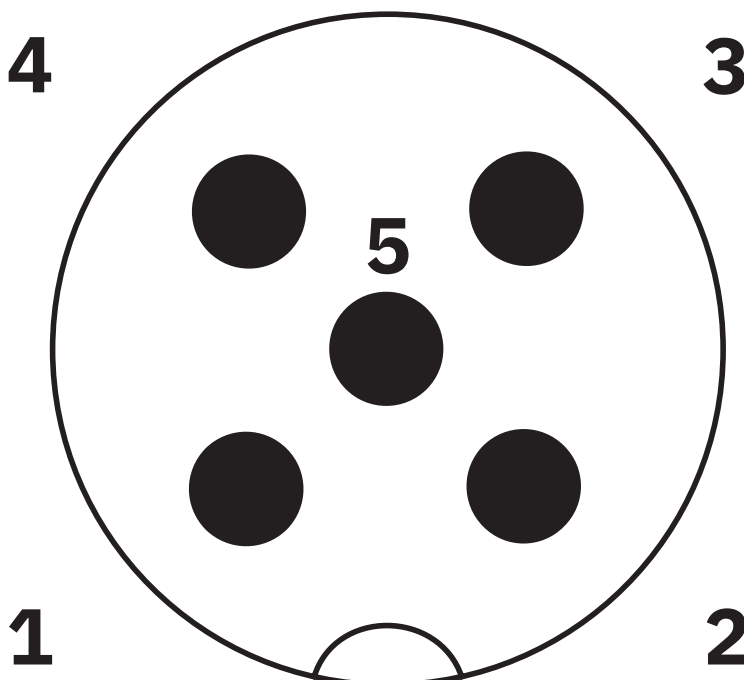


Pin assignment M12 male connector, 5-pos., A-coded, male side

SAC-5P-M12YF/M12FS-M12MS VP - Y distributor

1526253

<https://www.phoenixcontact.com/us/products/1526253>

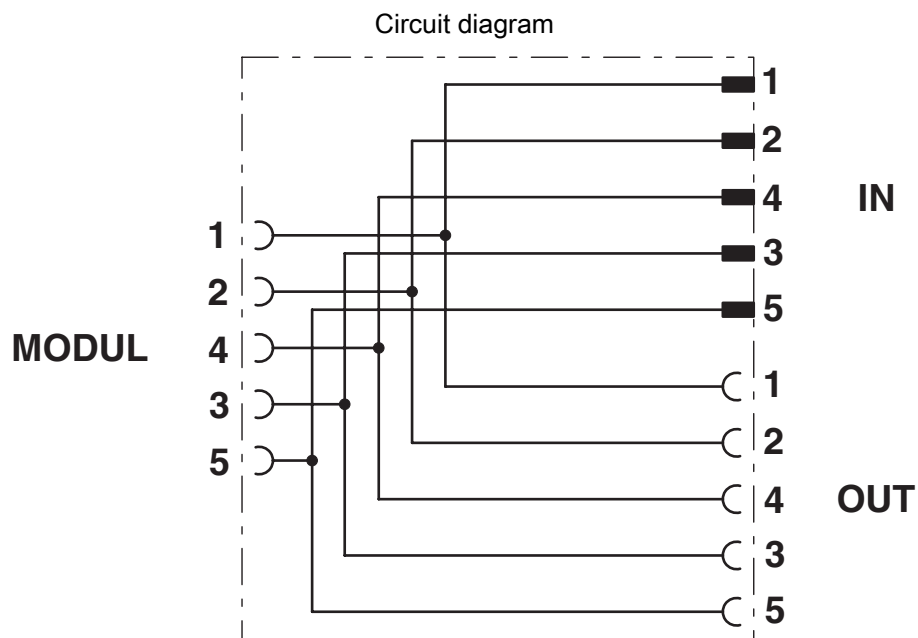

SAC-5P-M12YF/M12FS-M12MS VP - Y distributor



1526253

<https://www.phoenixcontact.com/us/products/1526253>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1526253>



EAC
Approval ID: EAC-Zulassung



EAC
Approval ID: RU C-DE.BL08.B.00511

	UL Listed Approval ID: E221474			
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	30 V	4 A	-	-

	cUL Listed Approval ID: E221474			
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	30 V	4 A	-	-

cULus Listed

SAC-5P-M12YF/M12FS-M12MS VP - Y distributor



1526253

<https://www.phoenixcontact.com/us/products/1526253>

Classifications

ECLASS

ECLASS-11.0	27440106
ECLASS-12.0	27440106
ECLASS-13.0	27440106

ETIM

ETIM 9.0	EC002925
----------	----------

UNSPSC

UNSPSC 21.0	31251500
-------------	----------

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	100f30db-55d8-4014-b81c-b75b8c1ccc2

1526253

<https://www.phoenixcontact.com/us/products/1526253>

Accessories

PROT-M12 - Screw plug

1680539

<https://www.phoenixcontact.com/us/products/1680539>



An M12 screw plug for the unoccupied M12 sockets of the sensor/actuator cable, boxes and flush-type connectors

PROT-M12 FS - Sealing cap

1560251

<https://www.phoenixcontact.com/us/products/1560251>



M12 sealing cap for unoccupied M12 plugs of the sensor/actuator cable, flush-type plugs and I/O devices in the field

SAC-5P-M12YF/M12FS-M12MS VP - Y distributor



1526253

<https://www.phoenixcontact.com/us/products/1526253>

PROT-M12 MS-PA-CHAIN - Screw plug

1430899

<https://www.phoenixcontact.com/us/products/1430899>

M12 sealing cap with fixing band, for sensor cables, for free M12 sockets



PROT-M12 FS-PA-CHAIN - Sealing cap

1430873

<https://www.phoenixcontact.com/us/products/1430873>

M12 sealing cap made of plastic with fixing band, for sensor cables, for free M12 plugs



SAC-5P-M12YF/M12FS-M12MS VP - Y distributor



1526253

<https://www.phoenixcontact.com/us/products/1526253>

TSD 04 SAC - Torque screwdriver

1208429

<https://www.phoenixcontact.com/us/products/1208429>



Torque screwdriver, with preset torque of 0.4 Nm and 4 mm hexagonal drive for M12 connectors

SAC BIT M12-D15 - Tool

1208432

<https://www.phoenixcontact.com/us/products/1208432>



Nut for assembling sensor/actuator cables with M12 connector and M12 connectors for assembly, with a knurl diameter of 15 mm, for 4 mm hexagonal drive

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com