


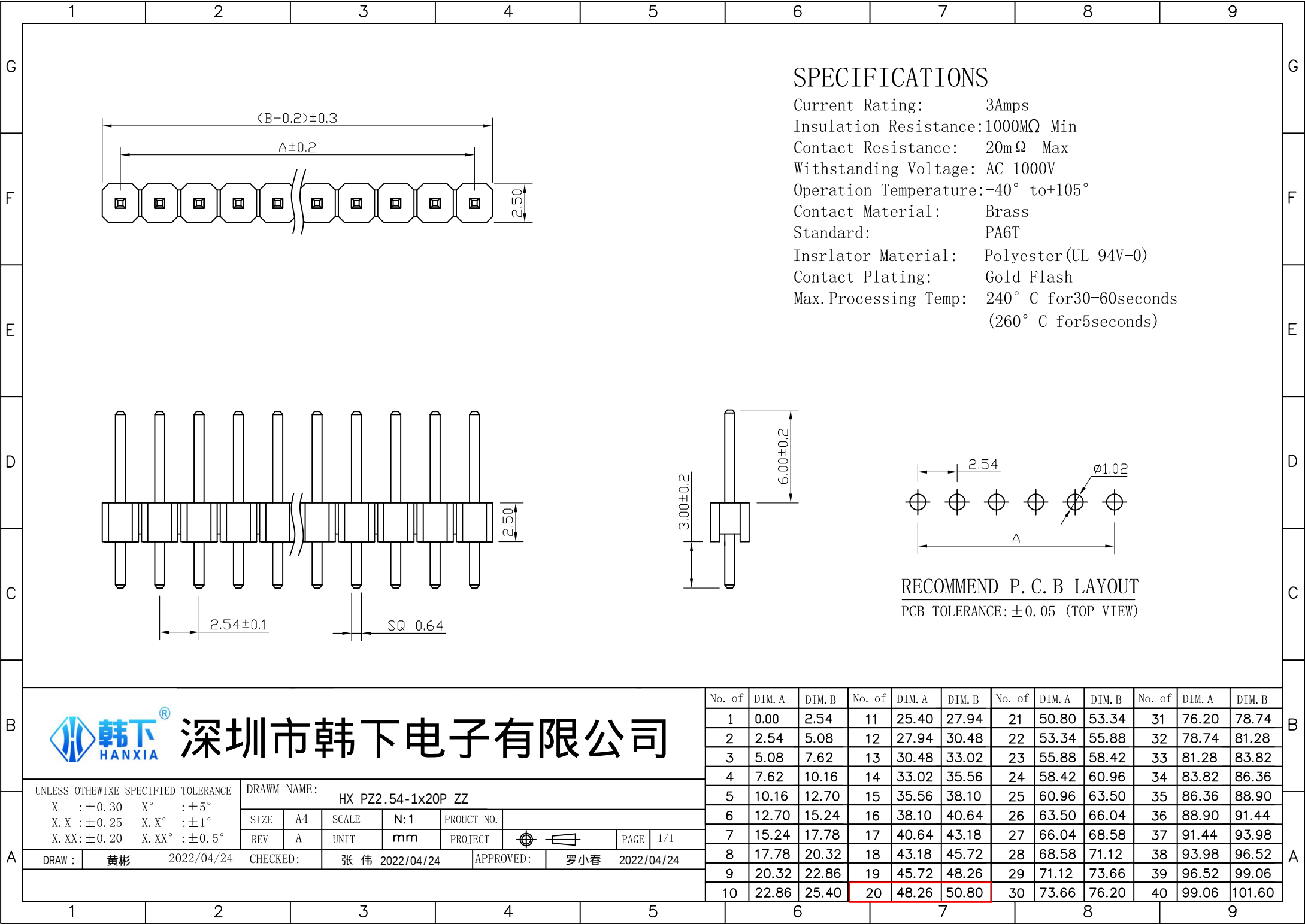

SPECIFICATIONS

Current Rating: 3Amps  
Insulation Resistance: 1000MΩ Min  
Contact Resistance: 20mΩ Max  
Withstanding Voltage: AC 1000V  
Operation Temperature: -40° to +105°  
Contact Material: Brass  
Standard: PA6T  
Insulator Material: Polyester (UL 94V-0)  
Contact Plating: Gold Flash  
Max. Processing Temp: 240° C for 30-60 seconds  
(260° C for 5 seconds)

RECOMMEND P. C. B LAYOUT  
PCB TOLERANCE: ±0.05 (TOP VIEW)



韩下®  
HANXIA

深圳市韩下电子有限公司

|                                                                                                                    |    |                                |          |       |            |            |                |
|--------------------------------------------------------------------------------------------------------------------|----|--------------------------------|----------|-------|------------|------------|----------------|
| UNLESS OTHERWISE SPECIFIED TOLERANCE<br>X : ±0.30 X° : ±5°<br>X.X : ±0.25 X.X° : ±1°<br>X.XX : ±0.20 X.XX° : ±0.5° |    | DRAWN NAME: HX PZ2.54-1x20P ZZ |          |       |            |            |                |
|                                                                                                                    |    | SIZE                           | A4       | SCALE | N:1        | PROUCT NO. |                |
|                                                                                                                    |    | REV                            | A        | UNIT  | mm         | PROJECT    |                |
| DRAW :                                                                                                             | 黄彬 | 2022/04/24                     | CHECKED: | 张伟    | 2022/04/24 | APPROVED:  | 罗小春 2022/04/24 |

| No. of | DIM. A | DIM. B | No. of | DIM. A | DIM. B | No. of | DIM. A | DIM. B | No. of | DIM. A | DIM. B |
|--------|--------|--------|--------|--------|--------|--------|--------|--------|--------|--------|--------|
| 1      | 0.00   | 2.54   | 11     | 25.40  | 27.94  | 21     | 50.80  | 53.34  | 31     | 76.20  | 78.74  |
| 2      | 2.54   | 5.08   | 12     | 27.94  | 30.48  | 22     | 53.34  | 55.88  | 32     | 78.74  | 81.28  |
| 3      | 5.08   | 7.62   | 13     | 30.48  | 33.02  | 23     | 55.88  | 58.42  | 33     | 81.28  | 83.82  |
| 4      | 7.62   | 10.16  | 14     | 33.02  | 35.56  | 24     | 58.42  | 60.96  | 34     | 83.82  | 86.36  |
| 5      | 10.16  | 12.70  | 15     | 35.56  | 38.10  | 25     | 60.96  | 63.50  | 35     | 86.36  | 88.90  |
| 6      | 12.70  | 15.24  | 16     | 38.10  | 40.64  | 26     | 63.50  | 66.04  | 36     | 88.90  | 91.44  |
| 7      | 15.24  | 17.78  | 17     | 40.64  | 43.18  | 27     | 66.04  | 68.58  | 37     | 91.44  | 93.98  |
| 8      | 17.78  | 20.32  | 18     | 43.18  | 45.72  | 28     | 68.58  | 71.12  | 38     | 93.98  | 96.52  |
| 9      | 20.32  | 22.86  | 19     | 45.72  | 48.26  | 29     | 71.12  | 73.66  | 39     | 96.52  | 99.06  |
| 10     | 22.86  | 25.40  | 20     | 48.26  | 50.80  | 30     | 73.66  | 76.20  | 40     | 99.06  | 101.60 |