



Rated cross-section $\leq 1.5 \text{ mm}^2$

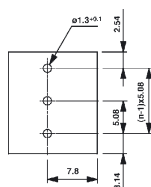

LM 5.08/135

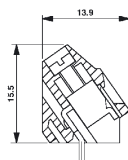

Technical Data		VDE	UL	CSA
Rated voltage	V	250*	300	300
Rated current	A	17.5	10	10
Clamping range max.	mm ² /AWG	1.5	14	14

*Overvoltage category III / Pollution severity 3

Additional technical data see page 53

Solder pin length	3.5 mm	3.5 mm
-------------------	--------	--------

3.5 m



3.5 mm

Colour  

Poles	Type	Cat. No.	Cat. No.	Qty.
2	LM 5.08/2/135	1716120000	1716060000	500
3	LM 5.08/3/135	1716130000	1716070000	500

[illegible]

Accessories	Page
Marking	42
Fixing	-
Miscellaneous	45

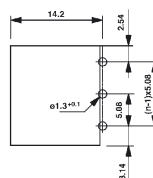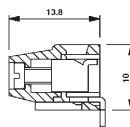

Technical Data		VDE	UL	CSA
Rated voltage	V	250*	300	300
Rated current	A	17.5	10	10
Clamping range max.	mm ² /AWG	1.5	14	14

*Overvoltage category III / Pollution severity 3

Additional technical data see page 53

Solder pin length	3.5 mm	3.5 mm
-------------------	--------	--------

3.5 m

3.5 mm



Colour

Poles	Type	Cat. No.	Cat. No.	Qty.
2	LM 5.08/2/180	1716100000	1716040000	500
3	LM 5.08/3/180	1716110000	1716050000	500

[illegible]

Accessories	Page
Marking	42
Fixing	-
Miscellaneous	45

LM 5.08/180

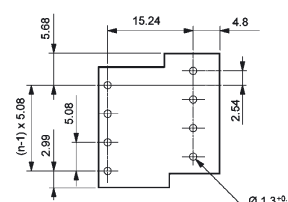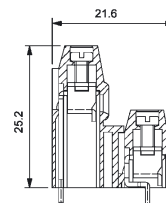

Technical Data		VDE	UL	CSA
Rated voltage	V	250*	300	300
Rated current	A	15.5	10	10
Clamping range max.	mm ² /AWG	1.5	14	14

*Overvoltage category III / Pollution severity 3

Additional technical data see page 53

Solder pin length	3.5 mm	3.5 mm
-------------------	--------	--------

3.5 n

3.5 mm

Colour

Poles	Type	Cat. No.	Cat. No.	Qty.
4	LM2N 5.08/4	1768850000	1769080000	50
6	LM2N 5.08/6	1768860000	1769090000	50

8	LM2N 5.08/8	1768870000	1769100000	50
10	LM2N 5.08/10	1768880000	1769100000	50
12	LM2N 5.08/12	1768890000	1769120000	50
14	LM2N 5.08/14	1768900000	1769130000	50
16	LM2N 5.08/16	1768910000	1769140000	20
18	LM2N 5.08/18	1768920000	1769150000	20
20	LM2N 5.08/20	1768930000	1769160000	20
22	LM2N 5.08/22	1768940000	1769170000	20
24	LM2N 5.08/24	1768950000	1769180000	10
26	LM2N 5.08/26	1768960000	1769190000	10
28	LM2N 5.08/28	1768970000	1769200000	10
30	LM2N 5.08/30	1768980000	1769210000	10
32	LM2N 5.08/32	1768990000	-	10
34	LM2N 5.08/34	1769000000	-	10
36	LM2N 5.08/36	1769010000	-	10
38	LM2N 5.08/38	1769020000	-	10
40	LM2N 5.08/40	1769030000	-	10
42	LM2N 5.08/42	1769040000	-	10
44	LM2N 5.08/44	1769050000	-	10
46	LM2N 5.08/46	1769060000	-	10
48	LM2N 5.08/48	1769070000	-	10

Accessories	Page
Marking	42
Fixing	-
Miscellaneous	45



**Rated cross-section
≤ 1.5 mm²**