



Rated cross-section ≤ 2.5 mm²

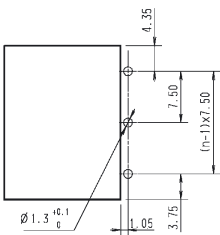

LP 7.50/180

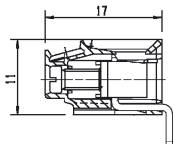

Technical Data		VDE	UL	CSA
Rated voltage	V	500*	300	300
Rated current	A	26	15	15
Clamping range max.	mm ² /AWG	4.0	12	12
*Overvoltage category III / Pollution severity 3				
Additional technical data see page 59				



Solder pin length 3.2 mm

Colour

Poles	Type	Cat. No.	Qty.
2	LP 7.50/2/180	1761370000	100
3	LP 7.50/3/180	1761380000	100

Accessories	Page
Marking	40
Fixing	46
Miscellaneous	46

 LP 7.62/90

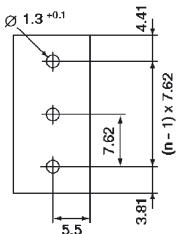

Technical Data		VDE	UL	CSA
Rated voltage	V	500*	300	300
Rated current	A	26	15	15
Clamping range max.	mm ² /AWG	4.0	12	12
*Overvoltage category III / Pollution severity 3				
Additional technical data see page 59				

Solder pin length 3.2 mm 4.5 mm

Colour

Poles	Type	Cat. No.	Cat. No.	Qty.
2	LP 7.62/2/90	1594460000	1697200000	100
3	LP 7.62/3/90	1594470000	1697210000	100

Accessories	Page
Marking	40
Fixing	46
Miscellaneous	46