
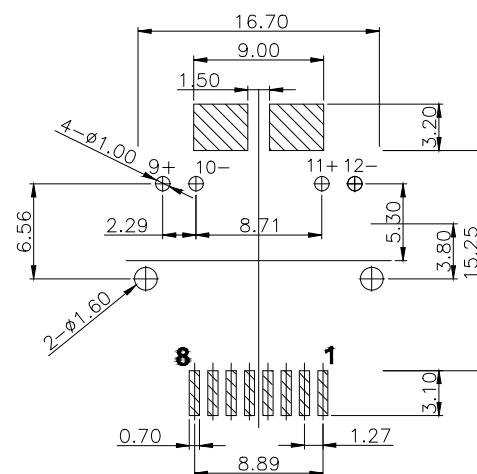
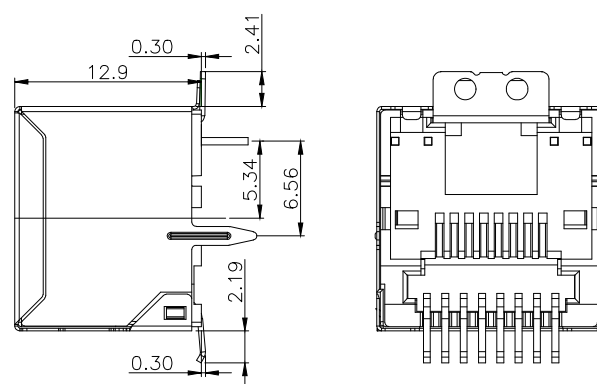


PCBLAYOUT T=1.6
TOL:±0.05

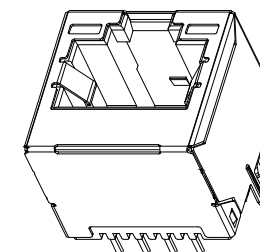

2. STORAGE

・-40℃~+85℃
・-40℃~+85℃

Standard LED Color	LED Wavelength	Forward(I _F)	Forward(V _F)		
Green	568nm	20mA	1.85-2.45V		
Yellow	585nm	20mA	1.7-2.2V		
6	1.4x3.2x4.8 平头半透明亮绿贴片	1	SPCC T=0.5mm		胶体半透明绿色黄绿光
5	1.4x3.2x4.8 平头半透明亮黄贴片	1	SPCC T=0.5mm		胶体半透明黄色黄绿光
4	RJ45 立式12.3H DIP有灯外壳	1	ES99 T=0.35mm		镀50u"
3	RJ45 立式12.3H端子	3	ES91 T=0.35mm		AW亮面100u"/NI 50u"
2	RJ45 立式12.3H DIP镀银半成品	1	LCP UL94V-0		
1	RJ45 立式12.3H有注有灯主体	1	LCP UL94V-0		
NO.	PART NAME	QTY	MATERIAL	PLATING & COLOR	

8	—
7	—
6	RX-
5	—
4	—
3	RX+
2	TX-
1	TX+
PIN序	説明

1	初版发行	
序号 No.	变更内容 MODIFY CONTENT	日期 MODIFY DATE

GENERAL TOLERANCE		制 图 DRAWING
DIM	TOL	审 核 CHECK
X. X	± 0.30	批 准 APPROVAL
X. XX	± 0.20	比 例 SCALE
X. XXX	± 0.10	投 影 Projection
Angle	$\pm 3.0^\circ$	


深圳市华灿天禄电子有限公司
 ShenzhenhuacantianluELECTRONICS CO.,LTD

产品名称 TITLE	网络插座(有壳带脚 带灯无柱H2.7)	版 本 REV.	A
产品料号 PART NO.	HC-RJ45-865-1-2-Q	单 位 UNITS	mm
材 料 MATERIAL		页 次 SHEET	1/