

HC-STA-D07-CHWSCM-1TGM25-PL-BK - Housing



1419264

<https://www.phoenixcontact.com/us/products/1419264>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Coupling housings D7, with single locking latch, material: PA, protective cover material: PA, cable outlets: 1, straight, M25, height: 60.5 mm, cable gland: with, protective cover: yes, Standard, for pin inserts

Commercial data

Item number	1419264
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF56
Product key	BF7APD
Catalog page	Page 516 (C-2-2019)
GTIN	4055626160153
Weight per piece (including packing)	44.2 g
Weight per piece (excluding packing)	42 g
Customs tariff number	85389099
Country of origin	CN

Technical data

Notes

General	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
---------	---


Product properties

Product type	Housing with locking latch
Housing type	Coupling housings
Product family	HC-STA-D07
Application	Standard
Type	D7
No. of cable outlets	1
Type of the screw connection	M25
Protective cover	yes
Shielded	no
Cable outlet	straight
Pg screw connection	with

Data management status

Article revision	01
------------------	----

Dimensions

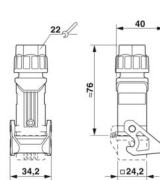Dimensional drawing	
Width	26.5 mm
Height	60.5 mm
Length	26.5 mm

Material specifications

Flammability rating according to UL 94	V0 (Housing)
	V0 (Interlock)
	V0 (Protective cover)
Housing material	PA
Material, protective cover	PA
Locking latch material	PA

Mechanical properties

Mechanical data

Type of the screw connection	M25
------------------------------	-----

HC-STA-D07-CHWSCM-1TGM25-PL-BK - Housing



1419264

<https://www.phoenixcontact.com/us/products/1419264>

Locking type	Latch
--------------	-------

Cable/line

External cable diameter	10 mm ... 16 mm
-------------------------	-----------------

Connection data

External cable diameter	10 mm ... 16 mm
-------------------------	-----------------

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66 (when plugged in or with locked protective cover)
Impact strength	IK06
Ambient temperature (operation)	-40 °C ... 125 °C

HC-STA-D07-CHWSCM-1TGM25-PL-BK - Housing


1419264

<https://www.phoenixcontact.com/us/products/1419264>



Drawings

Dimensional drawing

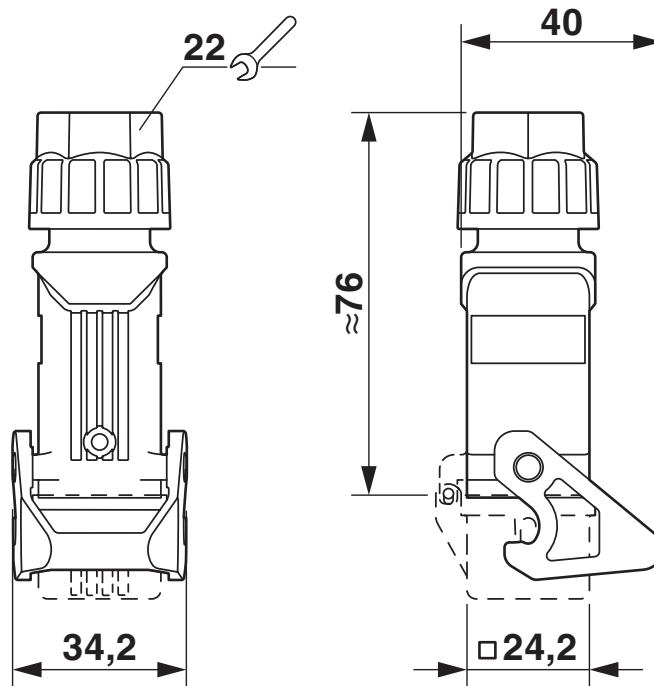

Dimensional drawing

1419264

<https://www.phoenixcontact.com/us/products/1419264>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1419264>

DNV

Approval ID: TAE000037S



EAC

Approval ID: RU C-DE.BL08.B.00511

1419264

<https://www.phoenixcontact.com/us/products/1419264>

Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com