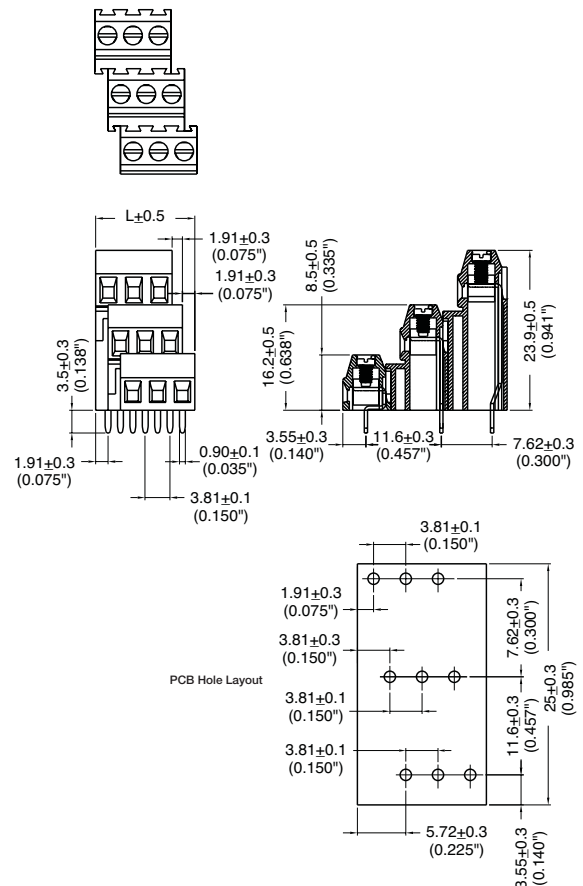


EM2803 Series**Euro-Mag Terminal Blocks**

Three Tier; 3.81 Centers; Modular

SPECIFICATIONS**Rating:** 10A, 300V**Center Spacing:** 0.150" (3.81mm)**Wire Range:** #16-26 AWG**Housing Material:** UL rated 94V0 Thermoplastic**Contact Material:** Brass Tin-Plated**Cage Clamp:** Brass, Nickel-Plated**Screw Size:** M2.0 Nickel-Plated Steel**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.**Torque Rating:** 2.5 lb-in.**Recommended PCB Hole Diameters:** 0.055" (1.40mm)**Construction:** Modular design features dovetails for interlocking to achieve longer lengths**Agency Information:**  US File E62622; CE Certified**EM280302****Dimensions - mm (in)**

Poles	L (mm)	Poles	L (mm)
2	11.43	8	34.29
3	15.24	9	38.10
4	19.05	10	41.90
5	22.86	11	45.70
6	26.67	12	49.50
7	30.48		

To convert to inches, divide by 25.4

Part Numbering System**Series****# of Poles****EM2803****02****02 - 12**