




Pin headers S2L 3.5/180

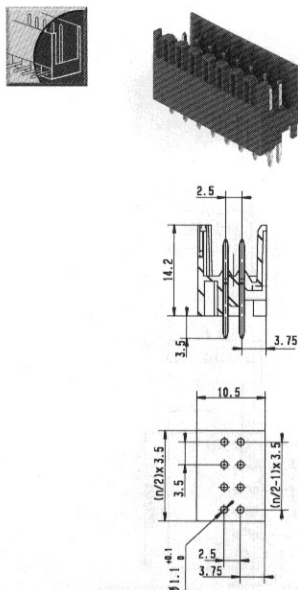


Technical data	VDE	UL	CSA
Rated voltage (V)	50*	150	50
Rated current (A)	7.5 ¹⁾	10	5

*Pollution severity 3 / Overvoltage category III

Additional technical data see page 210

Pin headers S2L 3.5/180G

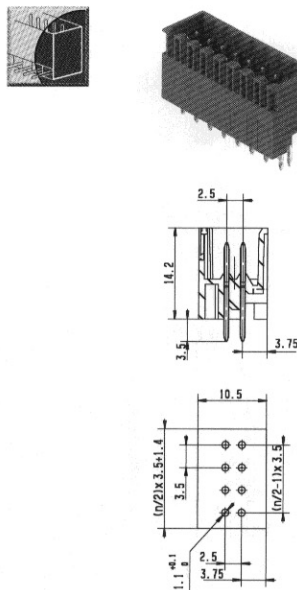


Technical data	VDE	UL	CSA
Rated voltage (V)	50*	150	50
Rated current (A)	7.5 ¹⁾	10	5

*Pollution severity 3 / Overvoltage category III

Additional technical data see page 210

Pin headers S2L 3.5/180F

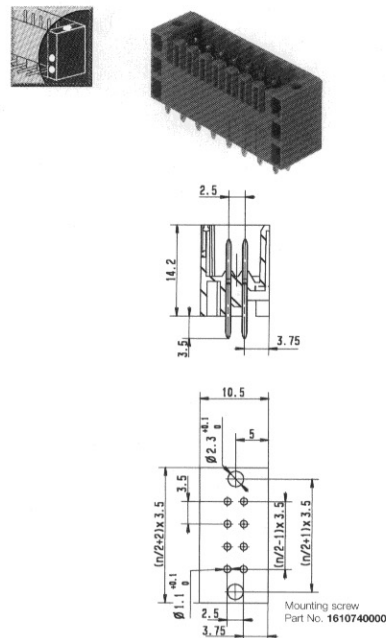

Technical data	VDE	UL	CSA
Rated voltage (V)	50*	150	50
Rated current (A)	7.5 ¹⁾	10	5

*Pollution severity 3 / Overvoltage category III

Additional technical data see page 210

Solder pin length		3.5 mm	3.5 mm		
tin-plated contacts					
Color					
Poles	Type	Part No.	Part No.	Qty.	
6	S2L 3.5/6/180	1729110000	1729270000	50	
8	S2L 3.5/8/180	1729120000	1729280000	50	
10	S2L 3.5/10/180	1729130000	1729290000	50	
12	S2L 3.5/12/180	1729140000	1729300000	50	
14	S2L 3.5/14/180	1729150000	1729310000	50	
16	S2L 3.5/16/180	1729160000	1729320000	50	
18	S2L 3.5/18/180	1729170000	1729330000	20	
20	S2L 3.5/20/180	1729180000	1729340000	20	
22	S2L 3.5/22/180	1729190000	1729350000	20	
24	S2L 3.5/24/180	1729200000	1729360000	20	
26	S2L 3.5/26/180	1729210000	1729370000	20	
28	S2L 3.5/28/180	1729220000	1729380000	20	
30	S2L 3.5/30/180	1729230000	1729390000	20	
32	S2L 3.5/32/180	1729240000	1729400000	20	
34	S2L 3.5/34/180	1729250000	1729410000	20	
36	S2L 3.5/36/180	1729260000	1729420000	20	

¹⁾ 36 poles = max. 6.8 A

Solder pin length		3.5 mm	3.5 mm		
tin-plated contacts					
Color					
Poles	Type	Part No.	Part No.	Qty.	
6	S2L 3.5/6/180G	1728790000	1728950000	50	
8	S2L 3.5/8/180G	1728800000	1728960000	50	
10	S2L 3.5/10/180G	1728810000	1728970000	50	
12	S2L 3.5/12/180G	1728820000	1728980000	50	
14	S2L 3.5/14/180G	1728830000	1728990000	50	
16	S2L 3.5/16/180G	1728840000	1729000000	50	
18	S2L 3.5/18/180G	1728850000	1729010000	20	
20	S2L 3.5/20/180G	1728860000	1729020000	20	
22	S2L 3.5/22/180G	1728870000	1729030000	20	
24	S2L 3.5/24/180G	1728880000	1729040000	20	
26	S2L 3.5/26/180G	1728890000	1729050000	20	
28	S2L 3.5/28/180G	1728900000	1729060000	20	
30	S2L 3.5/30/180G	1728910000	1729070000	20	
32	S2L 3.5/32/180G	1728920000	1729080000	20	
34	S2L 3.5/34/180G	1728930000	1729090000	20	
36	S2L 3.5/36/180G	1728940000	1729100000	20	

¹⁾ 36 poles = max. 6.8 A

Solder pin length		3.5 mm	3.5 mm		
tin-plated contacts					
Color					
Poles	Type	Part No.	Part No.	Qty.	
6	S2L 3.5/6/180F	1729430000	1729590000	50	
8	S2L 3.5/8/180F	1729440000	1729600000	50	
10	S2L 3.5/10/180F	1729450000	1729610000	50	
12	S2L 3.5/12/180F	1729460000	1729620000	50	
14	S2L 3.5/14/180F	1729470000	1729630000	50	
16	S2L 3.5/16/180F	1729480000	1729640000	50	
18	S2L 3.5/18/180F	1729490000	1729650000	20	
20	S2L 3.5/20/180F	1729500000	1729660000	20	
22	S2L 3.5/22/180F	1729510000	1729670000	20	
24	S2L 3.5/24/180F	1729520000	1729680000	20	
26	S2L 3.5/26/180F	1729530000	1729690000	20	
28	S2L 3.5/28/180F	1729540000	1729700000	20	
30	S2L 3.5/30/180F	1729550000	1729710000	20	
32	S2L 3.5/32/180F	1729560000	1729720000	20	
34	S2L 3.5/34/180F	1729570000	1729730000	20	
36	S2L 3.5/36/180F	1729580000	1729740000	20	

¹⁾ 36 poles = max. 6.8 A

Accessories	Page
Mounting	-
Marking	190
Coding	193
Miscellaneous	198

Accessories	Page
Mounting	-
Marking	190
Coding	193
Miscellaneous	198

Accessories	Page
Mounting	188
Marking	190
Coding	193
Miscellaneous	198