


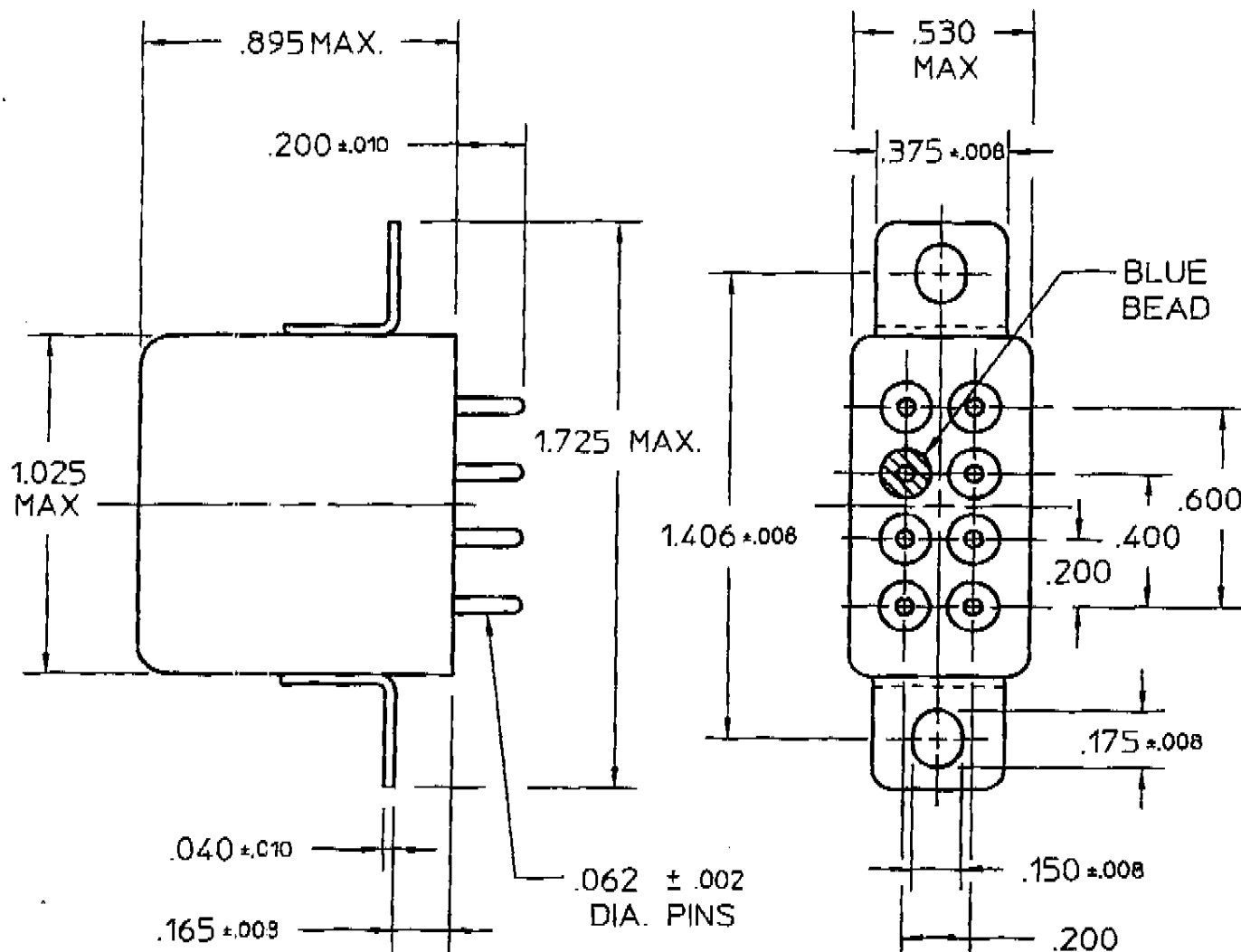

REV. 1 10/7/98

COIL: @ 25°C

RESISTANCE 300 OHMS ± 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.0 VDC

MUST RELEASE 7 VDC MAX, 1.0 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 50 g's 11 MS. DURATION

TEMPERATURE -65 °C TO +125 °C


NOTES: OPERATE & RELEASE 10 MS MAX.

OPERATE BOUNCE 2 MS MAX.

RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

BLUE BEAD

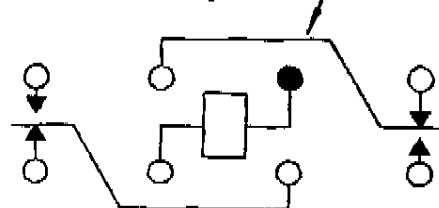

CONTACT RATING: 10 AMPS 28 VDC
RESISTIVE, 4 AMPS 28 VDC INDUCTIVE
100,000 OPERATIONS

DR. R.B. 4/22/96 CK. 10/7/98

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. SCHALTBAU
CUST. NO. 28420568540

TYPE '07' RELAY

A07A939BC1-0361

2. Hd. Mr. Brunner

NUCLETRON
ELECTRONIC

Vertriebs-GmbH
Gärtnerstraße 60 · 80992 München
Postfach 50 0180 · 80971 München
Telefon (0 89) 14 90 02-0
Telefax (0 89) 14 90 02-41