

RC-12P2N8A0000 - Contact insert



1598196

<https://www.phoenixcontact.com/us/products/1598196>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Contact insert, M23, number of positions: 12, contact connection type: Pin, Crimp connection, series: NC, RC, RM, TU, UC

Commercial data

Item number	1598196
Packing unit	10 pc
Minimum order quantity	1 pc
Sales key	AB31
Product key	ABRAFT
GTIN	4046356219617
Weight per piece (including packing)	1.87 g
Weight per piece (excluding packing)	1.5 g
Customs tariff number	85389099
Country of origin	DE

RC-12P2N8A0000 - Contact insert



1598196

<https://www.phoenixcontact.com/us/products/1598196>

Technical data

Notes

Order information:	Order crimp contacts Ø 1 mm separately
--------------------	--

Product properties

Product type	Contact insert
Series	NC
	RC
	RM
	TU
	UC
Application	Signal
Number of positions	12
Connection profile	12
Coding	N
Thread type	M23

Data management status

Article revision	04
------------------	----

Electrical properties

Contact

Contact diameter	1 mm
Max. current	8 A
Nominal voltage U_N	48 V AC 74 V DC
Overvoltage category	III
Degree of pollution	3
Rated surge voltage	1.5 kV

Connection data

Connection method	Crimp connection
-------------------	------------------

Material specifications

Insulator material	PA66
--------------------	------

Connector

Direction of rotation	Counter direction
-----------------------	-------------------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (storage/transport)	15 °C ... 25 °C
Permissible humidity (storage/transport)	50 % ... 65 %

RC-12P2N8A0000 - Contact insert


1598196

<https://www.phoenixcontact.com/us/products/1598196>



Drawings

Schematic diagram

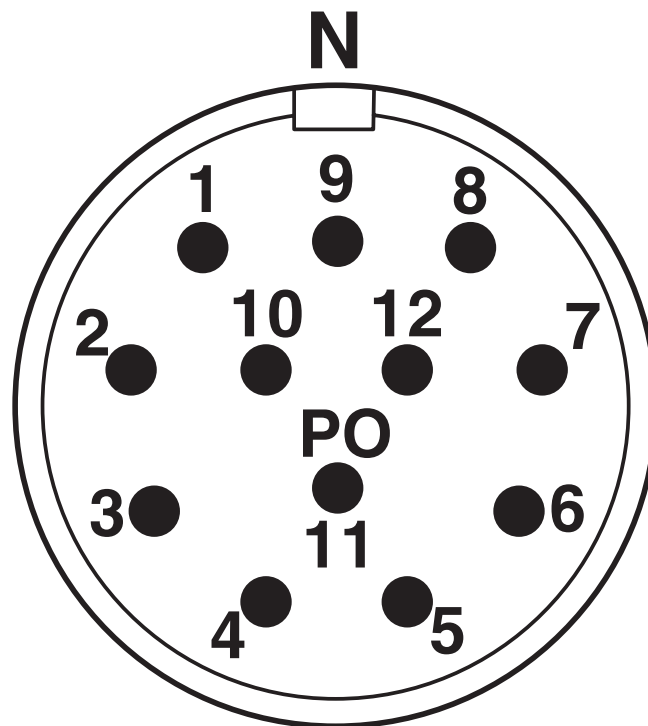

Connector pin assignment

RC-12P2N8A0000 - Contact insert



1598196

<https://www.phoenixcontact.com/us/products/1598196>

Classifications

ECLASS

ECLASS-11.0	27440223
ECLASS-12.0	27440223
ECLASS-13.0	27440223

ETIM

ETIM 9.0	EC003557
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

RC-12P2N8A0000 - Contact insert



1598196
<https://www.phoenixcontact.com/us/products/1598196>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com