

## EuroMag Series PCB Mount Pluggable Terminal Blocks

### EM3108 Series

#### Euro-Mag Terminal Blocks

Pluggable Block; Front Entry (Mates with EM2575 Series); 5.08 Centers

#### SPECIFICATIONS

**Rating:** 16A, 300V

**Center Spacing:** 0.20" (5.08mm)

**Wire Range:** #14-24 AWG

**Housing Material:** UL rated 94V0 Thermoplastic

**Contact Material:** Brass Tin-Plated

**Cage Clamp:** Brass, Nickel-Plated

**Screw Size:** M2.6 Nickel-Plated Steel

**Operating Temperature:** 105°C (221°F) max., -40°C (-40°F) min.

**Torque Rating:** 4.5 lb-in.


**Construction:** Mold-to-Length

**Agency Information:**  File E62622; CE Certified



EM310808

#### Dimensions - mm (in)

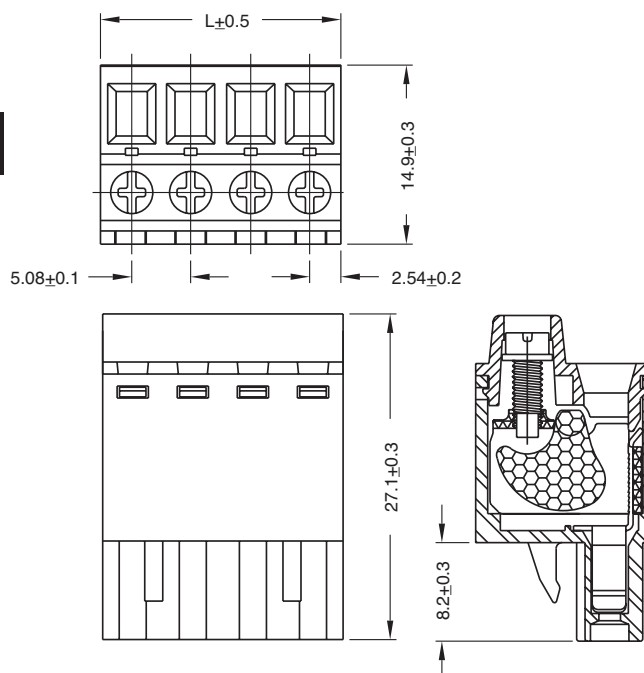

| Poles | L (mm) | Poles | L (mm) |
|-------|--------|-------|--------|
| 2     | 10.16  | 14    | 71.12  |
| 3     | 15.24  | 15    | 76.20  |
| 4     | 20.32  | 16    | 81.28  |
| 5     | 25.40  | 17    | 86.36  |
| 6     | 30.48  | 18    | 91.44  |
| 7     | 35.45  | 19    | 96.52  |
| 8     | 40.64  | 20    | 101.60 |
| 9     | 45.72  | 21    | 106.68 |
| 10    | 50.80  | 22    | 111.76 |
| 11    | 55.88  | 23    | 116.84 |
| 12    | 60.96  | 24    | 121.92 |
| 13    | 66.04  |       |        |

To convert to inches, divide by 25.4

### Part Numbering System

Series

# of Poles

EM3108

02 to 24

Mating Header: EM2575 pg. 101