

EM2565 Series

Euro-Mag Terminal Blocks

Depluggable Block (Mates with EM2575 Header), 5.08 Centers

SPECIFICATIONS

Rating: 15A, 300V

Center Spacing: .200" (5.08 mm)

Consult factory for .400" (10.16 mm)

Wire Size: #12-22 AWG

Housing Material: Green Polyamide Type 6/6, 94VO

Contact Material: Brass Tin Plated

Screw Size: M 3x5 Zinc Plated Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Torque Rating: 4.5 in-lb.

Construction: Mold to Length

Approvals: UL E62622; CSA LR701941; CE Certified

TABLE A

Position	L (mm)	Position	L (mm)
02	10.16	14	71.12
03	15.24	15	76.20
04	20.32	16	81.28
05	25.40	17	86.36
06	30.48	18	91.44
07	35.56	19	96.52
08	40.64	20	101.60
09	45.72	21	106.68
10	50.80	22	111.76
11	55.88	23	116.84
12	60.96	24	121.92
13	66.04		

To convert to inches, divide by 25.4





EM256508VR





EM256506H

EM2565 Series
HORIZONTAL

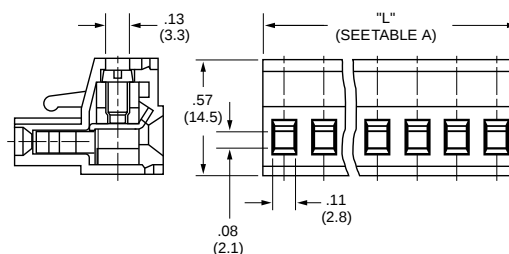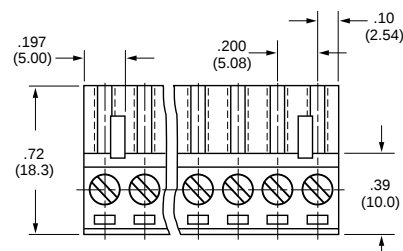

VERTICAL

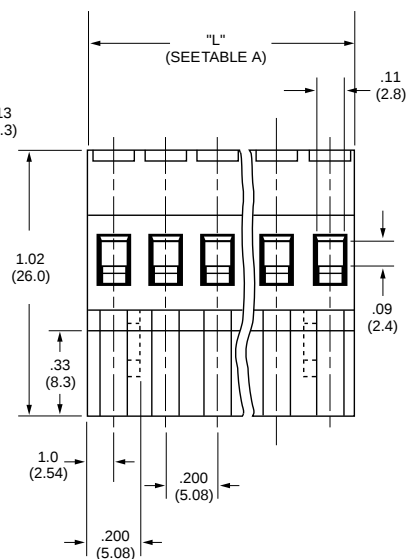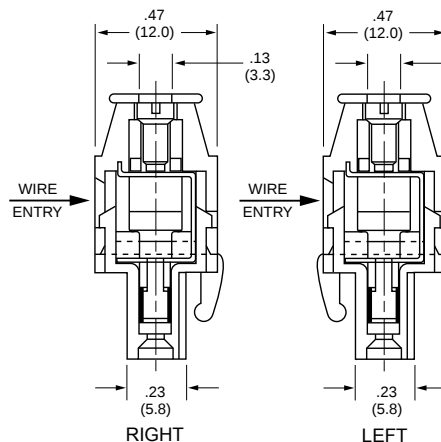

Part Numbering System

Series	# of Positions	Orientation	Wire Entry (Vertical Only)
EM2565	02 to 24	H - horizontal V - vertical	L - left R - right