

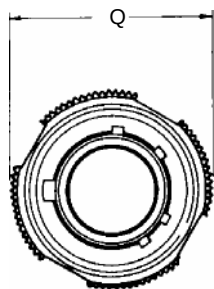


TV06R, CTV06, BS-C6176 D38999/26 JN1034C


Straight plug

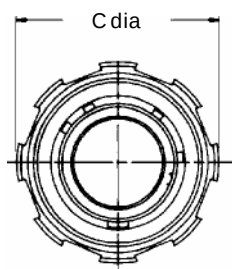

- * TV06RW- ... Olive Drab Aluminium
- * TVS06RF- ... Electroless Nickel Aluminium
- * TVS06RB- ... Marine Aluminium Bronze
- * TVS06RS- ... Electroless Nickel Stainless Steel
- * TVS06RK- ... Firewall Stainless Steel
- * CTV06RW- ... Olive Drab Composite
- * CTVS06RF Electroless Nickel Composite
- * BS9520 G0003 C6176 ... BS Specification
- * D38999/26-... Mil Specification
- * JN1034C... Olive drab Aluminium

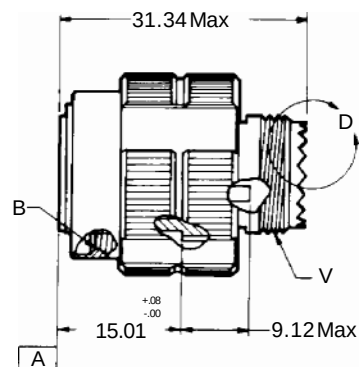


- * TVS06RB-... (W88) Marine Aluminium Bronze
- * CECC75-201-002A-... Marine Aluminium Bronze

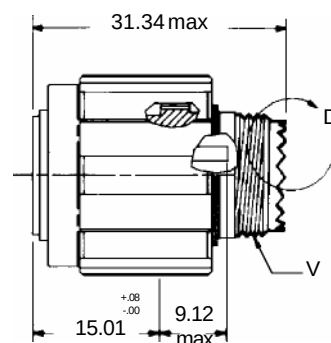

From surface A
42.06 Max

View D enlarged for
size 8 coaxial use only

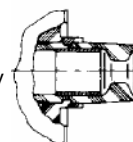

* To complete order number, see "how to order" pages

Shell Size	MS Shell Size Code	C Dia Max	B Thread 0.1P.0.3L.TS.2B Code	Q Max	V Thread Metric
9	A	21.1	.6250	21.82	M12X1.6g
11	B	23.8	.7500	24.62	M15X1.6g
13	C	28.2	.8750	28.98	M18X1.6g
15	D	31.4	1.0000	32.16	M22X1.6g
17	E	36.5	1.1875	35.33	M25X1.6g
19	F	39.3	1.2500	38.10	M28X1.6g
21	G	42.5	1.3750	41.28	M31X1.6g
23	H	45.3	1.5000	44.45	M34X1.6g
25	J	48.4	1.6250	47.63	M37X1.6g

All dimensions for reference only