

UC-0000000NNDU - Housing for circular connector



1606050

<https://www.phoenixcontact.com/us/products/1606050>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Housing for circular connector, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1242062



Commercial data

Item number	1606050
Packing unit	8 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	AB31
Product key	ABRAIE
GTIN	4046356256971
Weight per piece (including packing)	178.575 g
Weight per piece (excluding packing)	168.3 g
Customs tariff number	85389099
Country of origin	DE

UC-0000000NNDU - Housing for circular connector



1606050

<https://www.phoenixcontact.com/us/products/1606050>

Technical data

Notes

Order information:	Order contact inserts separately
--------------------	----------------------------------

Product properties

Product type	Circular connector housing
Series	UC
Application	Signal
Shielded	yes
Thread type	M23

Material specifications

Housing material	Metal
Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Gasket and O-ring material	FPM

Connector

Type	angled
------	--------

Cable/line


External cable diameter	6.5 mm ... 14.5 mm
-------------------------	--------------------

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP67
Ambient temperature (operation)	-20 °C ... 125 °C
Altitude	2000 m

Drawings

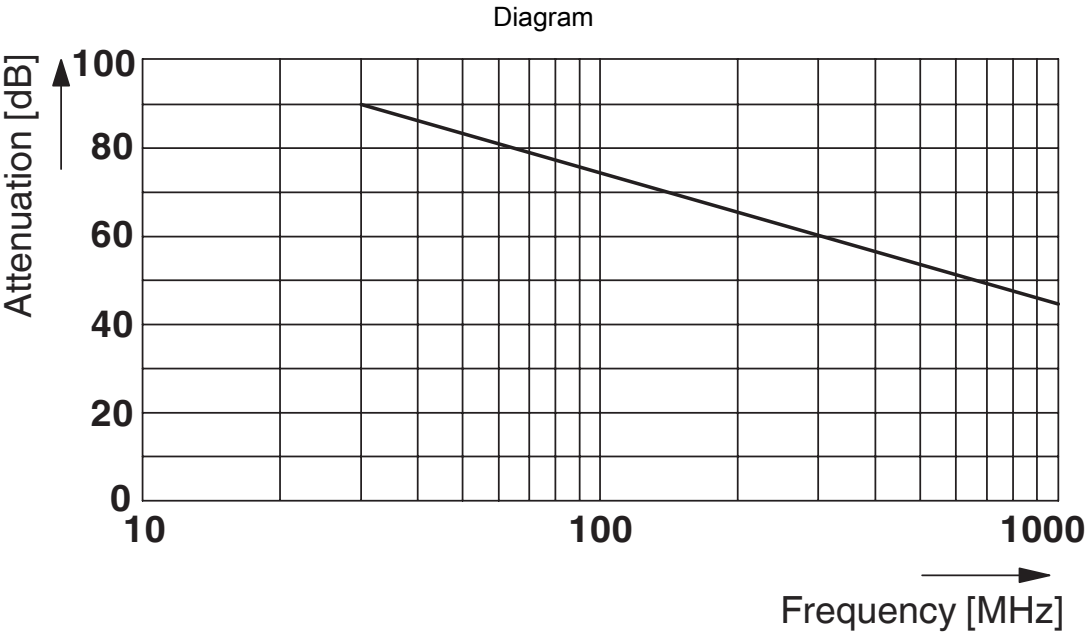

UC-0000000NNDU - Housing for circular connector



1606050

<https://www.phoenixcontact.com/us/products/1606050>

Classifications

ECLASS

ECLASS-11.0	27440102
ECLASS-12.0	27440116
ECLASS-13.0	27440224

ETIM

ETIM 9.0	EC003556
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

UC-0000000NNDU - Housing for circular connector



1606050
<https://www.phoenixcontact.com/us/products/1606050>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)
China RoHS	
Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.
EU REACH SVHC	
REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	0dd84ab3-591c-4e98-a8a3-9cc0be1801e4

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com