

REV. 3  
DCO 102710


COIL: @ 25°C	
RESISTANCE	170 OHMS ± 10%
NOMINAL VOLTAGE	18.0 VDC
MUST OPERATE	9.7 VDC
MUST RELEASE	1.15 VDC MIN, 5.4 VDC MAX

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE & RELEASE 15 MS MAX.
	OPERATE BOUNCE 5 MS MAX.
	RELEASE BOUNCE 5 MS MAX.

CUST. OPL  
CUST. NO. M5757/23-042 REV.

"07" RELAY

CUSTOMER DATA SHEET

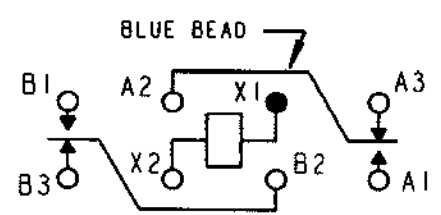

TERMINAL VIEW

CONTACT RATING:	10 AMPS 28 VDC
	5 AMPS 115 VAC/400 HZ RESISTIVE
	50,000 OPERATIONS

DR.R.B. 11/11/91 CK. TLG 8-17-01

**CII Technologies**  
advanced control electronic solutions

B07D932BZ2-0358

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[B07D932BZ2-0358](#)