

# RC-00000004300 - Panel mounting base



1592591

<https://www.phoenixcontact.com/us/products/1592591>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Panel mounting base, series: RC, straight, Screw locking mechanism, M23, Radial O-ring, 4xM3, panel thickness min.: 2.7 mm, panel thickness max.: 3.5 mm, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1240233

## Commercial data

Item number	1592591
Packing unit	40 pc
Minimum order quantity	1 pc
Sales key	AB31
Product key	ABRAFP
GTIN	4046356191685
Weight per piece (including packing)	27.695 g
Weight per piece (excluding packing)	27.695 g
Customs tariff number	85366990
Country of origin	DE

# RC-00000004300 - Panel mounting base

1592591

<https://www.phoenixcontact.com/us/products/1592591>




## Technical data

### Product properties

Product type	Panel mounting base
Series	RC
Application	Signal
Thread type	M23

### Dimensions

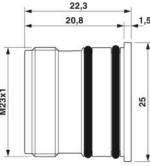Dimensional drawing	
Panel thickness	2.7 mm ... 3.5 mm

### Material specifications

Housing material	Metal
------------------	-------

### Connector

Type	straight
------	----------

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP67
----------------------	------

### Mounting

Mounting	4x M3
----------	-------


# RC-00000004300 - Panel mounting base

1592591


<https://www.phoenixcontact.com/us/products/1592591>



## Drawings

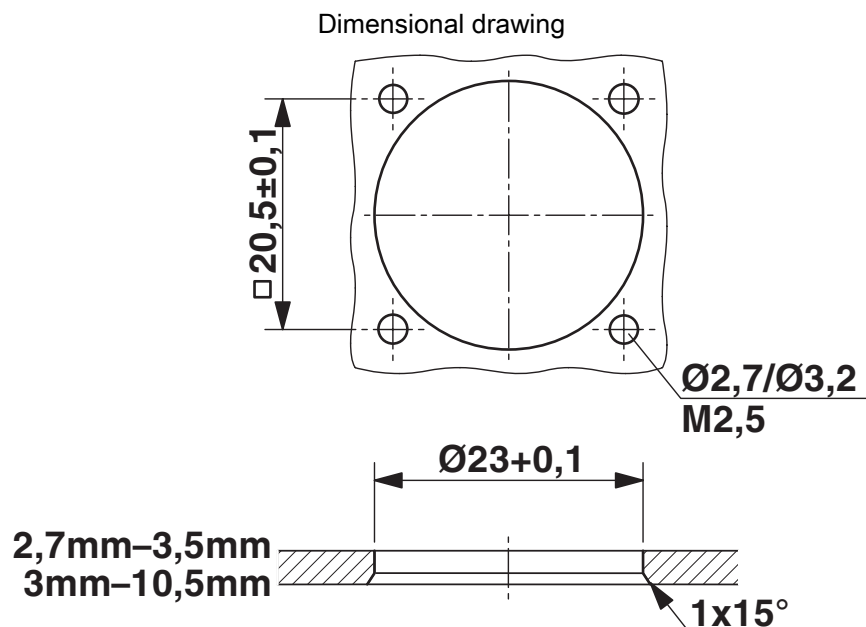

## Installation dimensions

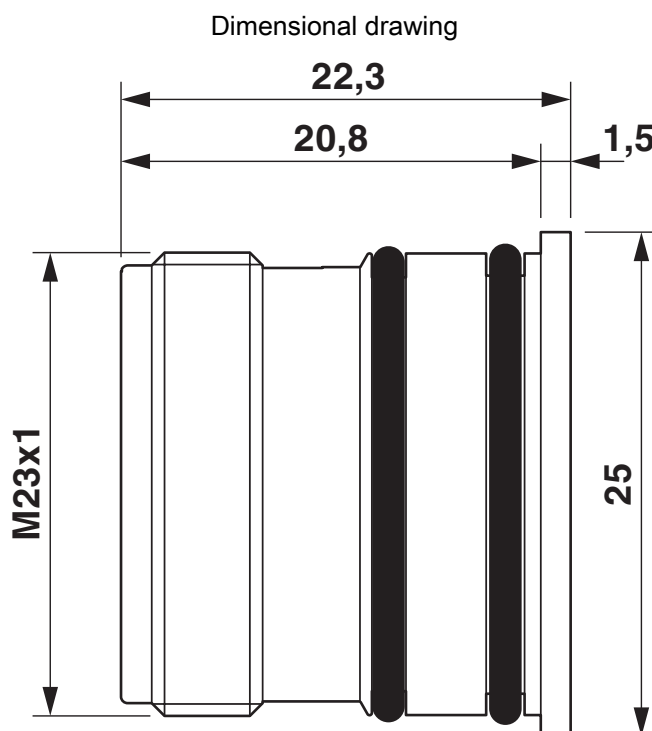

## Dimensional drawing

# RC-00000004300 - Panel mounting base



1592591

<https://www.phoenixcontact.com/us/products/1592591>

## Classifications

### ECLASS

ECLASS-11.0	27440224
ECLASS-12.0	27440224
ECLASS-13.0	27440224

### ETIM

ETIM 9.0	EC003556
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# RC-00000004300 - Panel mounting base



1592591  
<https://www.phoenixcontact.com/us/products/1592591>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)
China RoHS	
Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.
EU REACH SVHC	
REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	37250c56-e556-489e-a3db-5694322f1a94

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)