


E12514



Ethernet RJ45 connector

RJ45-Steckverbinder

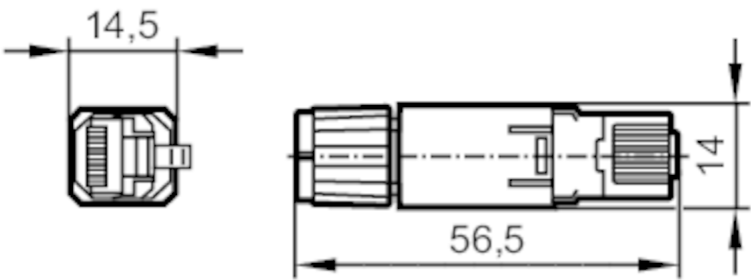

Operating conditions

Ambient temperature	[°C]	-10...60
Protection		IP 20

Mechanical data

Weight	[g]	10.4
--------	-----	------

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

insulation displacement terminals: 0.34 mm²; Cable sheath: Ø 4.5...8 mm; AWG 22

Electrical connection - plug

Connector: 1 x RJ45, straight

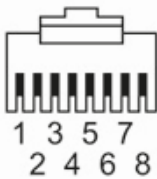

E12514



Ethernet RJ45 connector

RJ45-Steckverbinder

Connection

