


(1,00mm) .03937"

FSI SERIES

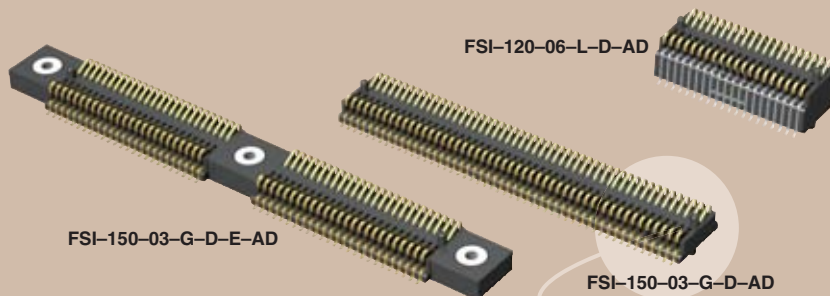

LOW PROFILE & ELEVATED ONE PIECE

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?FSI

Insulator Material:

Liquid Crystal

Polymer

Contact Material:

BeCu

Current Rating:

1A @ 80°C ambient

Operating Temp Range:

-55°C to +125°C

Plating:

Au over 50µ" (1,27µm) Ni

RoHS Compliant:

Yes

Processing:

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0,10mm) .004" max (05-35)

(0,15mm) .006" max (40-50)

Compression Board:

Gold Pads required



APPLICATION SPECIFIC OPTION

Metric insert, no alignment pin, top side alignment pin and bottom side alignment pin. Call Samtec.

Choice of board stacking profiles

(1,00mm)
.03937"

Short version or optional threaded inserts



• Threaded insert option

 
Note: Applications requiring 40-50 positions without threaded inserts, please contact Samtec Interconnect Processing Group.

Note: Some lengths, styles and options are non-standard, non-returnable.

Also Available


Low Profile

See SEI Series.




.100" (2,54mm) Pitch

 See SIB Series.





High Density

 See GFZ Series.



Flex Data Link




See FSIF Series.

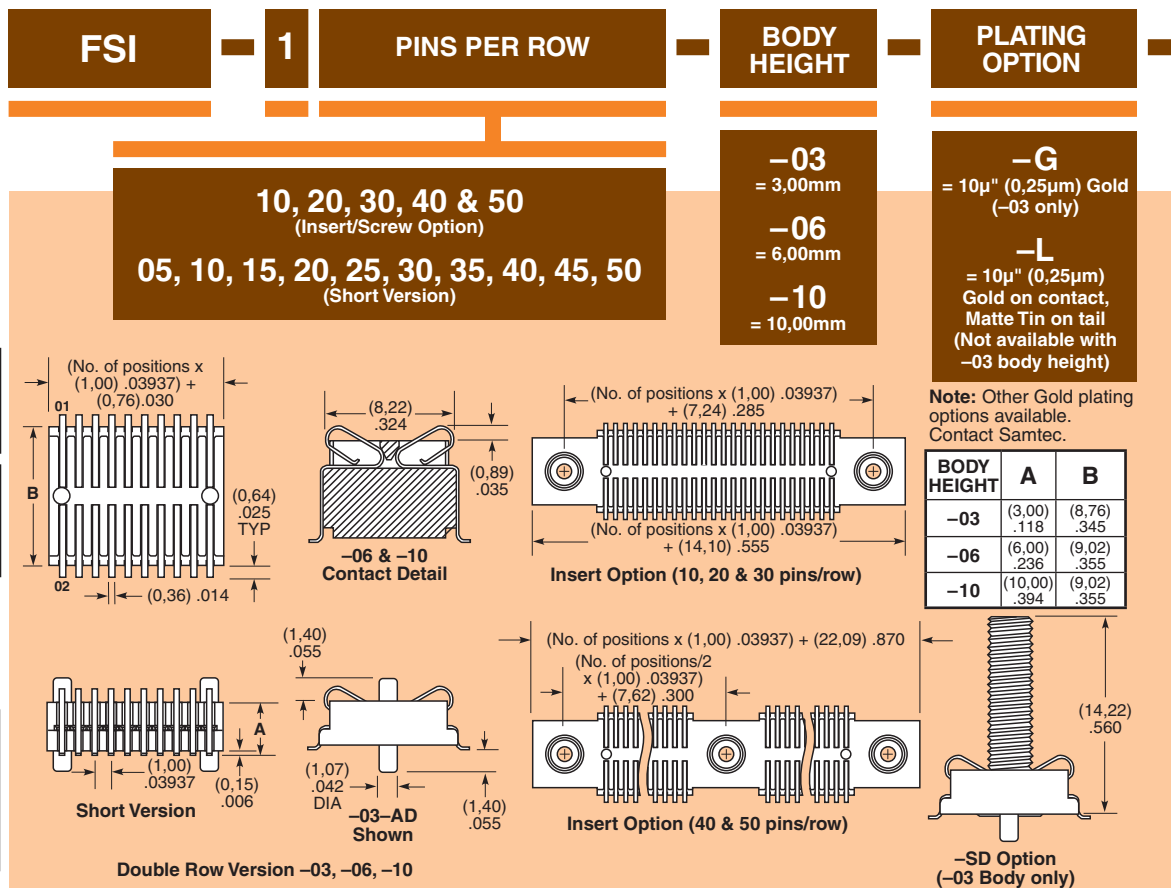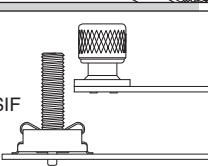

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC SILICON VALLEY • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292 SAMTEC ISRAEL • Tel: 972-3-7526600
 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-61103766 SAMTEC TAIWAN • Tel: 886-2-2735-6109
 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9512 7747 SAMTEC SOUTH AFRICA • Tel: 27 11 452 8112

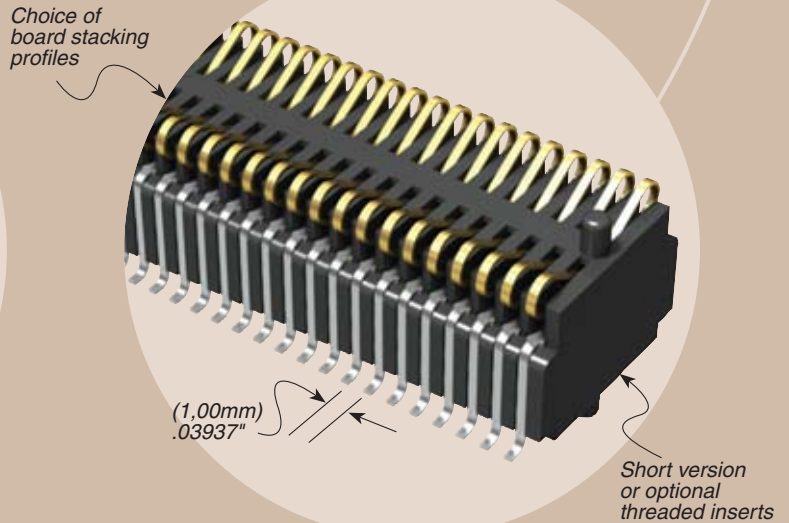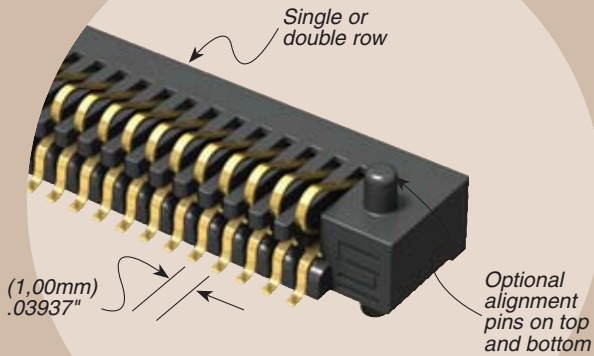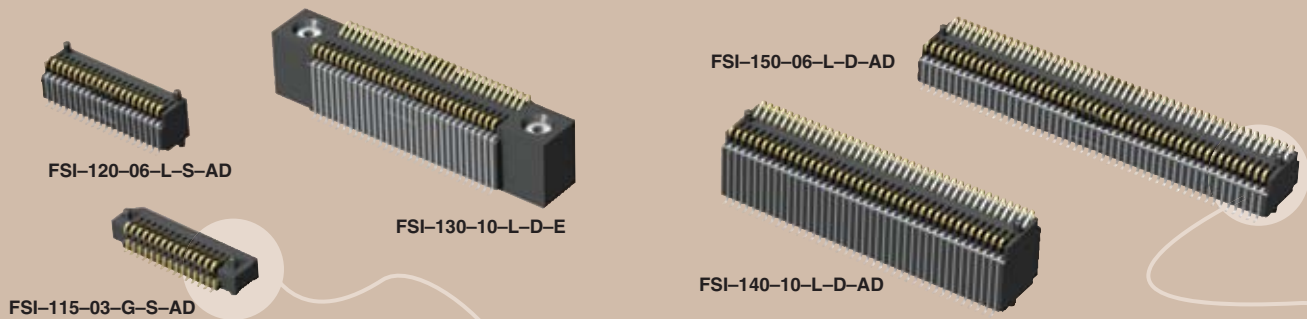

ROW OPTION

—S
= Single Row

—D
= Double Row

INSERT OPTION

Leave blank for Short Version
(No screw down inserts or holes)

—E
= #2-56 x 1/16" screw thread
(—SD not available)

ALIGNMENT OPTION

Leave blank for
no Alignment Pin

—AD
= Alignment Pin
Top & Bottom

OTHER OPTION


—SD
= Screw Down
(For mating with FSIF Series Flex Data Link)
(10, 20, 30 positions only)
(Threaded insert option not available)
(Not available with —S row option or
—06 & —10 body height)

—WT
= Weld Tab
(Available with —S row option &
—06 & —10 body height only)

—K
= Polyimide Film Pick & Place Pad
(40 & 50 position with threaded
insert option only)

—P
= Plastic Pick & Place Pad
(5,08mm) .200" x (12,45mm) .490"
(40 & 50 not available with —E)
(Not available with —S row option
or —03 body height)

—TR
= Tape & Reel Packaging

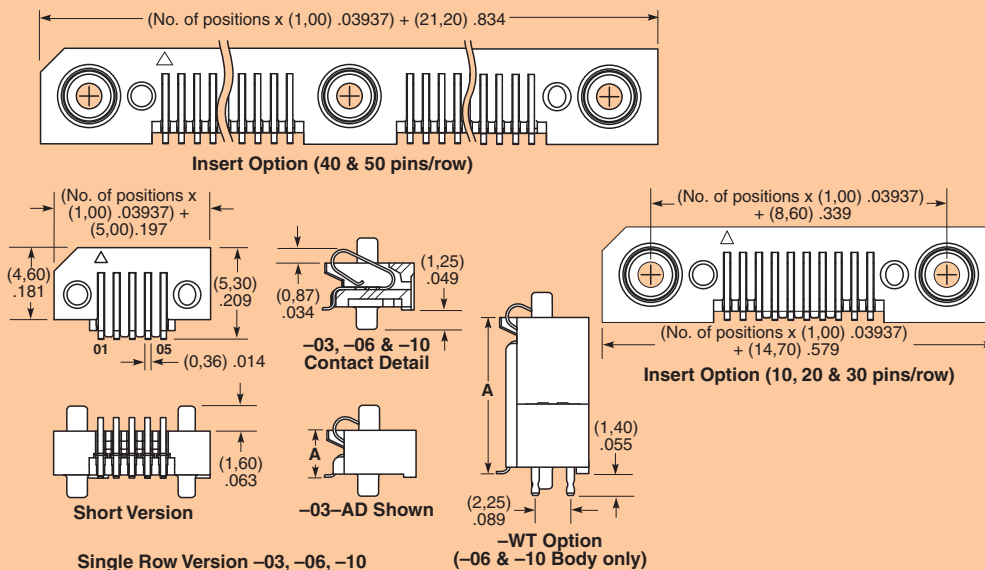

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC SILICON VALLEY • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292 SAMTEC ISRAEL • Tel: 972-3-7526600
SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-61103766 SAMTEC TAIWAN • Tel: 886-2-2735-6109
SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9512 7747 SAMTEC SOUTH AFRICA • Tel: 27 11 452 8112