
 


Omnimate Range - Pitch 7.62 mm

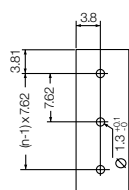

Pin headers SL 7.62/180



Technical Data		VDE	UL	CSA
Rated voltage	V	500*	300	300
Rated current	A	15	10	10

*Overvoltage category III / Pollution severity 3

Additional technical data see page 225

Solder pin length



3.2 mm

4.5 mm

Colour

Poles	Type	Cat. No.	Cat. No.	Qty.
2	SL 7.62/2/180	1625030000	1624700000	100
3	SL 7.62/3/180	1625040000	1624710000	100
4	SL 7.62/4/180	1625050000	1624720000	100
5	SL 7.62/5/180	1625060000	1624730000	50
6	SL 7.62/6/180	1625070000	1624740000	50
7	SL 7.62/7/180	1625080000	1624750000	50
8	SL 7.62/8/180	1625090000	1624760000	50
9	SL 7.62/9/180	1625100000	1624770000	50
10	SL 7.62/10/180	1625110000	1624780000	50
11	SL 7.62/11/180	1625120000	1624790000	50
12	SL 7.62/12/180	1625130000	1624800000	50

 Pin headers SL 7.62/180B

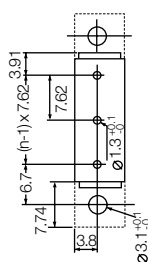

Technical Data		VDE	UL	CSA
Rated voltage	V	500*	300	300
Rated current	A	15	10	10

*Overvoltage category III / Pollution severity 3

Additional technical data see page 225

Solder pin length

3.2 mm

4.5 mm

Colour

Poles	Type	Cat. No.	Cat. No.	Qty.
2	SL 7.62/2/180B	1625250000	1624920000	100
3	SL 7.62/3/180B	1625260000	1624930000	100
4	SL 7.62/4/180B	1625270000	1624940000	100
5	SL 7.62/5/180B	1625280000	1624950000	50
6	SL 7.62/6/180B	1625290000	1624960000	50
7	SL 7.62/7/180B	1625300000	1624970000	50
8	SL 7.62/8/180B	1625310000	1624980000	50
9	SL 7.62/9/180B	1625320000	1624990000	50
10	SL 7.62/10/180B	1625330000	1625000000	50
11	SL 7.62/11/180B	1625340000	1625010000	50
12	SL 7.62/12/180B	1625350000	1625020000	50

Accessories	Page
Fixing	-
Marking	196
Coding	199
Miscellaneous	-

Accessories	Page
Fixing	193
Marking	196
Coding	199
Miscellaneous	-