



MMT-120-01-S-SV

(2,00 mm) .0787"

MMT-XV SERIES

MMT-116-01-S-DV

SMT TERMINAL STRIPS

Mates with:
SSM, MMS, TCSD

Features:

- Single or double row
- Vertical or horizontal pin orientation. (See Full Line Catalog for horizontal specifications.)
- Alignment pins
- Locking clips
- Pick & Place Pads
- Polarization option
- Molded with high temperature Liquid Crystal Polymer for infrared or vapor phase reflow soldering.
- Mates with Samtec surface mount sockets, or with other Samtec high temperature through-hole sockets for mixed technology applications.

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com/MMT

Insulator Material:

Black Liquid Crystal Polymer

Flammability Rating:

UL 94V-0

Insulation Resistance:

5000 MΩ min

Operating Temp Range:

-55°C to +105°C with Tin;

-55°C to +125°C with Gold

Dielectric Withstanding Voltage:

600 VAC

Terminal Material:

Phosphor Bronze

Plating:

Au, PdNi or Sn over

50μ" (1,27 μm) Ni

RoHS Compliant:

Yes

Processing:

Lead-Free Solderable:






Yes, with Matte Sn plating

Lead Coplanarity:

.006" (0,15 mm) max

Note:

Some lengths, styles and options are non-standard, non-returnable.

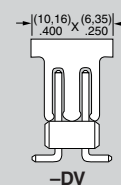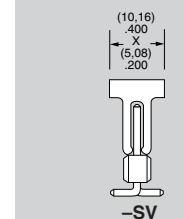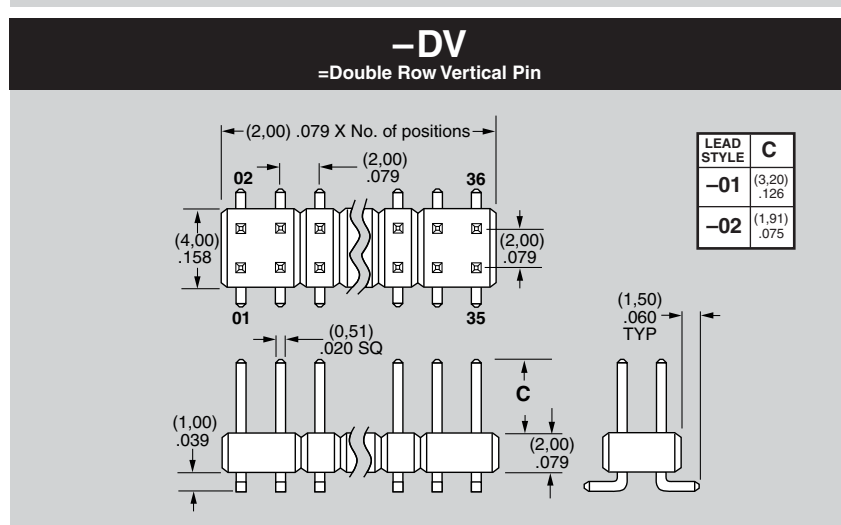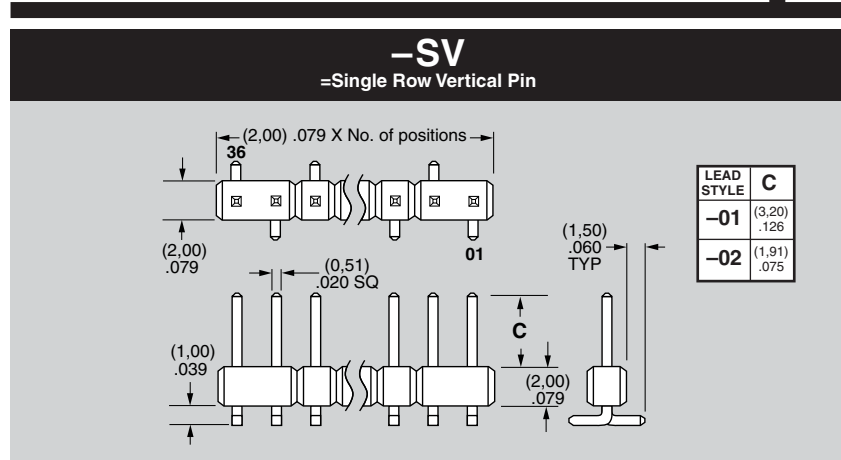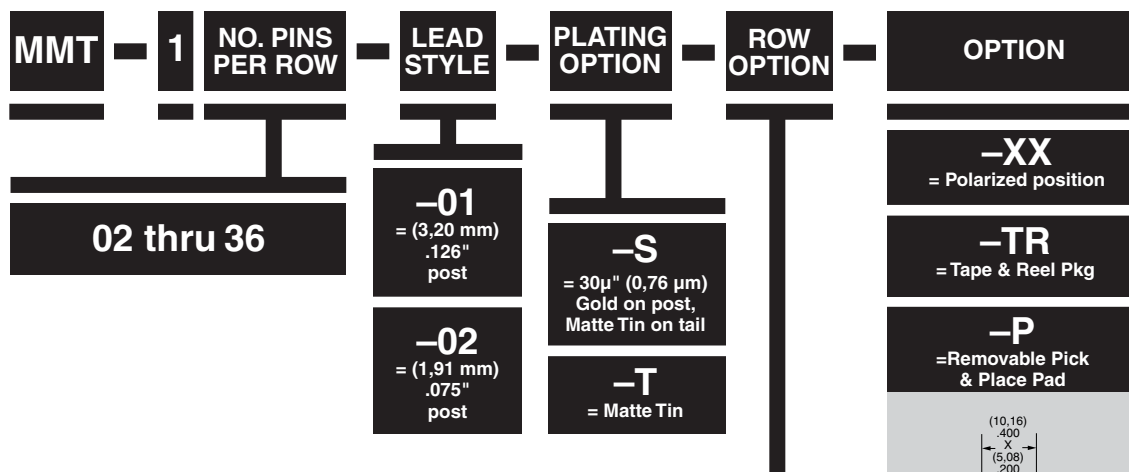

APPLICATION SPECIFIC OPTIONS

Alignment pins & locking clips available. Call Samtec.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
 SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683