




SMA CONNECTORS

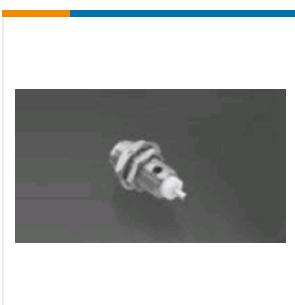

TE CONNECTIVITY (TE)

2004 8207 92

AMP | SMA

1051032-1

TE Internal Number: 1051032-1

Mil-Spec: M39012/83-3207

Alias ID: 2004-8207-92

Always EU RoHS/ELV Compliant

Applies To **Coaxial Cable**

Panel Mount **With**

Body Material **Stainless Steel**

Body Plating Finish **Passivated**

Panel Mount Retention Type **Bulkhead**

✓ Active

[PRODUCT DRAWING](#)
English

[3D PDF](#)

Product Drawings

OSM BULKHEAD FEEDTHRU CABLE JACK - COMPRESSION CRIMP M39012-83-3207 CAT "F"

[PDF \(TIFF AVAILABLE\)](#)
English

OSM BULKHEAD FEEDTHRU CABLE JACK - COMPRESSION CRIMP M39012-83-3207 CAT "F"

[PDF \(TIFF AVAILABLE\)](#)
English

CAD Files

[3D PDF](#)

PDF

[3D](#)

[Customer View Model](#)

2D_DXF.ZIP

English

[Customer View Model](#)

3D_IGS.ZIP

English

[Customer View Model](#)

3D_STP.ZIP

English

Instruction Sheets

Instruction Sheet (U.S.)

[SMA Bulkhead Feed Through Cable Jack 1051032-1 \(Compression Crimp Attachment\)](#)

PDF

English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Applies To

Coaxial Cable

RF Connector Type

SMA

Connector Type	JKR	
Connector Style	Jack	
Cable Type	RG 405	
Product Type	Connector - RF	
Shrink Tubing	Without	
Dielectric Material	PTFE	
Retractable Collar	Without	
Grade	Military	
Sealed	Panel	
<hr/>		
Configuration Features	Snap-Lock	Without
<hr/>		
Electrical Characteristics	Impedance (Ω)	50
<hr/>		
Signal Characteristics	Frequency (GHz)	18
<hr/>		
Body Features	Body Material	Stainless Steel
	Body Plating Finish	Passivated
	Body Style	Straight
	Gasket Material	Silicone Rubber
	Ferrule Material	Stainless Steel
	Ferrule Plating Material	Passivated
<hr/>		
Contact Features	Captivation Method	Mechanical
	Center Contact Plating Material	Gold
	Center Contact	With
	Center Contact Material	Beryllium Copper
	Captivated Contacts	With
<hr/>		
Termination Features	Cable Termination Type	Crimp
	Crimp Type	Compression
<hr/>		
Mechanical Attachment	Panel Mount	With
	Panel Mount Retention Type	Bulkhead
	Lockwasher Plating Finish	Passivated
	Polarized	No
	Lockwasher Material	Stainless Steel

Panel Attachment Style	Rear Mount
Mounting Nut Material	Stainless Steel
Dimensions	Length
	17.7 mm [.696 in]
Industry Standards	Military Category
	F
Packaging Features	Packaging Method
	Package
Product Compliance	Statement of Compliance PDF
	VIEW ALL PRODUCT COMPLIANCE