

# OWS-1330TA-8

## Circular speaker

General speaker available for multiple applications. Doesn't require any sealed back cavity.




### Characteristics

Size (ØxH) [mm]	13.0x3.0	
Sensitivity [dB SPL]	74.0±3 dB	1.0W/1.0m, free air
Impedance [Ω]	8	
Power [W]	0.5 / 0.8	nom /max, free air
F0 [Hz]	1050	Free air
Termination	Terminals	Comment


Specifications are subject to change without prior notice. Upon request Ole Wolff can supply further specifications, simulation parameters etc.

### Mechanical drawing

Unless otherwise specified, tolerance: ±0.3 (unit: mm)

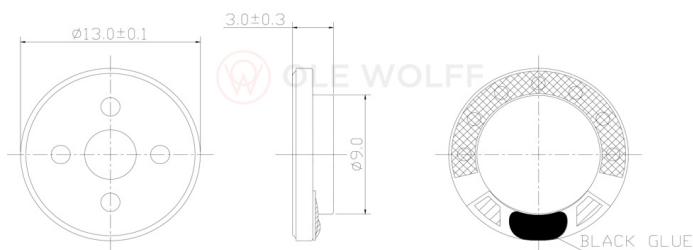

### SPL

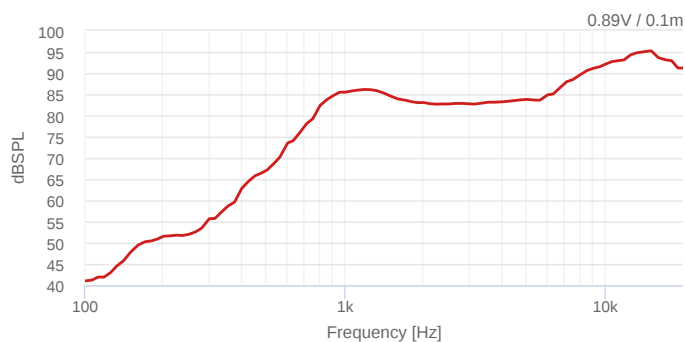

### THD



### |Z|

