


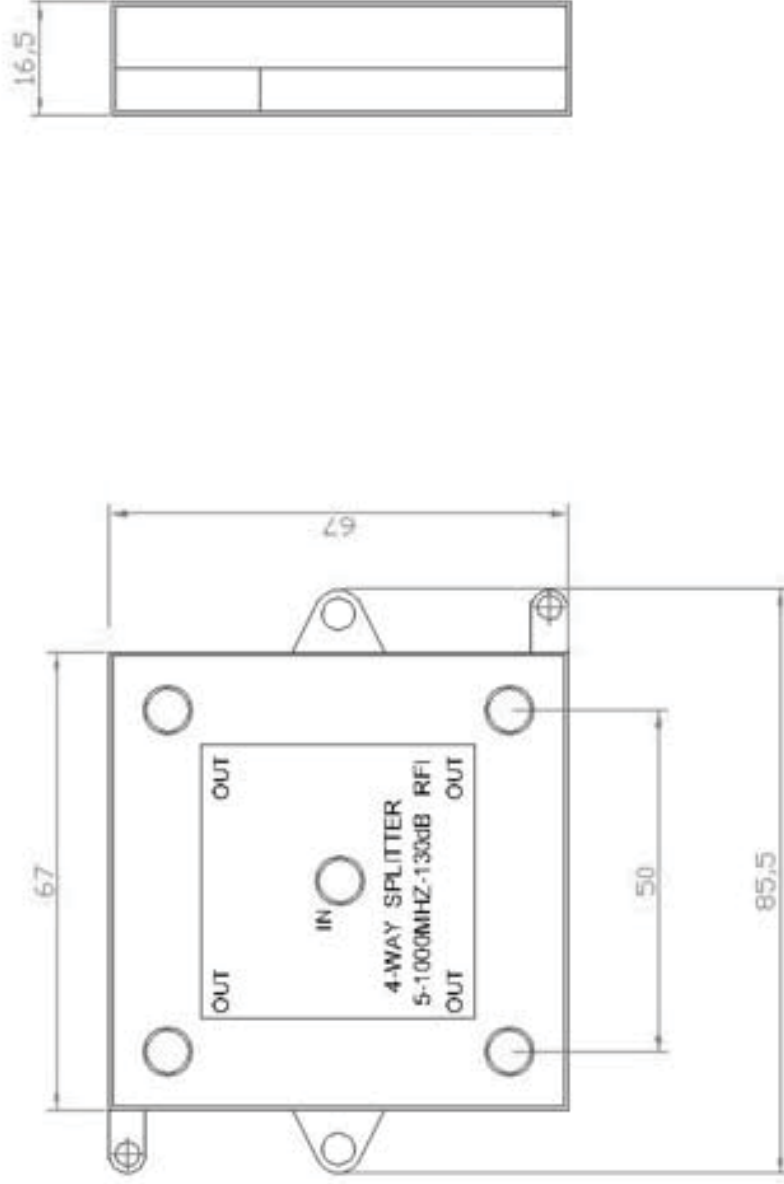

PARAMETERS

NÚ		Product introduction
1		Zinc alloy die casting products.
2		Surface using tin plating
3		This back cover with tin seal to seal
4		Inch thread F head
5		To fix the main body on both sides
6		achieve superior sealing and anti disturbance ability
7		This internal use of superior circuit design

Remark: +/-0.5MM EXCLUDED

PARAMETERS

ITEM NO	SPEC	FREQUENCY RANGE	INSERTION LOSS(dB)	ISOLATION(dB)	RETURN LOSS(dB)
VSP-4140	5-1000MHZ	5-47MHZ	- 11 dB	-25dB	-16dB
		47-470MHZ	- 11.5 dB	-23dB	-16dB
		470-860MHZ	-12.5 dB	-25dB	-16dB
		860-1000MHZ	- 13.5 dB	-22dB	-16dB

ITEM	VSP-4140		
DRAW	Sally	Date	2014.7.29
SCALE	1:1	UNITS	mm