



 

MICRO SWITCH
FREEPORT, ILLINOIS, U.S.A.
A DIVISION OF HONEYWELL

FED. MFG. CODE 91928



SWITCH - ENCLOSED

CATALOG LISTING

1EN204-15B

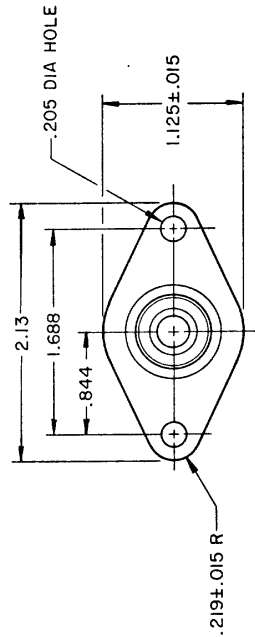

CIRCUIT DIAGRAM

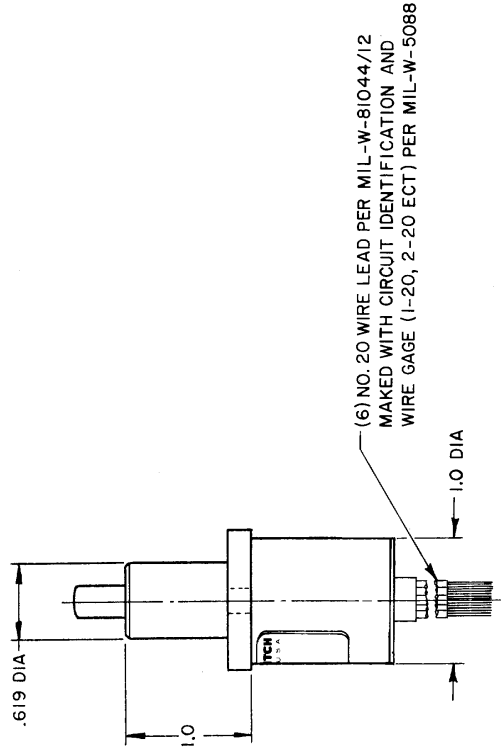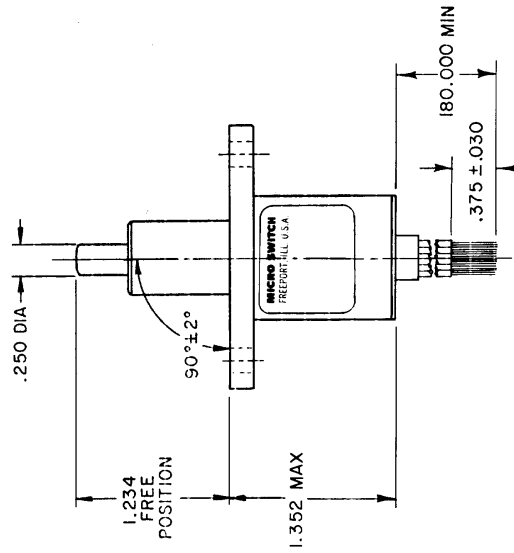

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF MINNEAPOLIS-HONEYWELL REGULATOR CO. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH.

CHARACTERISTICS

OPERATING FORCE - 6-12 LB

RELEASE FORCE - 30 LB MAX

PRETRAVEL - 4 LB MIN

DIFFERENTIAL TRAVEL - .040 MAX

OVERTRAVEL - .020 MAX

250 MIN

28 VDC

SEA LEVEL

50,000 FT.

RES

4

IND

2

MOTOR

4

ELECTRICAL DATA

CONTACT ARRANGEMENT

S P D T (2)

DO NOT SCALE PRINT

SCALE FULL

UNLESS OTHERWISE

NOTED

DIMENSIONS ARE IN INCHES

TOLERANCES ARE:

ONE PLACE (.01)

TWO PLACE (.001)

THREE PLACE (.0005)

FOUR PLACE (.0002)

WEIGHT

11.0 OZ MAX

NOTES

1 - CORROSION RESISTANT STEEL ENCLOSURE

2 - SWITCH SEALED PER MIL-S-8805 SYMBOL 4

3 - CIRCUIT DIAGRAM AND CATALOG LISTING ARE SHOWN ON NAMEPLATE

4 - COINCIDENCE OF OPERATING AND RELEASING POINTS: .010 OF PLUNGER TRAVEL