

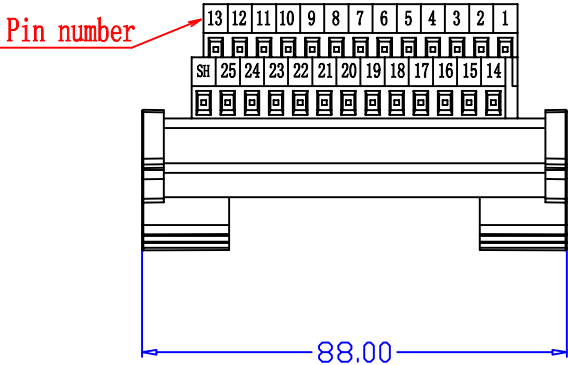
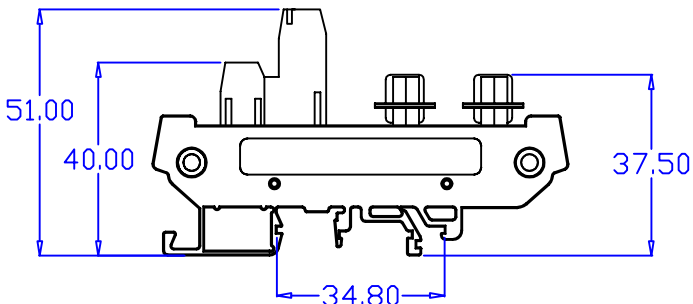


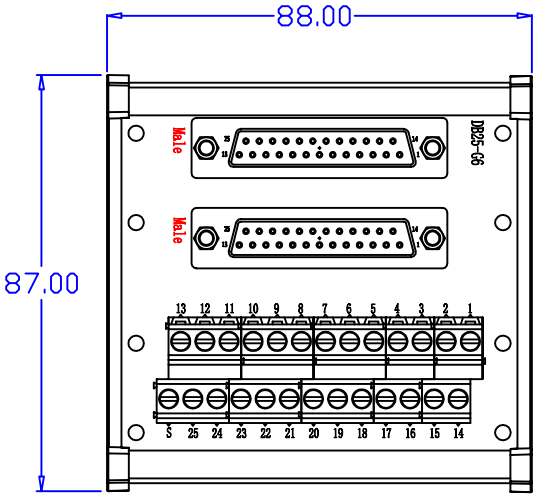

parameter table:

| Num | Category                    | Describe                                  |
|-----|-----------------------------|-------------------------------------------|
| 1   | Max Current                 | 1 A                                       |
| 2   | Cable gauge (AWG)           | 16-26 AWG                                 |
| 3   | D_SUB connector:            | 冲针 Pin                                    |
| 4   | PCB Material                | FR4                                       |
| 5   | D_SUB Withstanding voltage  | 300V AC/MINUTE                            |
| 6   | D_SUB Operating temperature | -10℃ to 70℃                               |
| 7   | Rated voltage according to  | UL:No                                     |
| 8   | Rated current according to  | UL:No                                     |
| 9   | D_SUB Material:             | INSULATOR:PBT 30%GF; CONTACT:COPPER ALLOY |
| 10  | Box size w/label            | L115*W95*H54mm /                          |
| 11  | Packing                     |                                           |

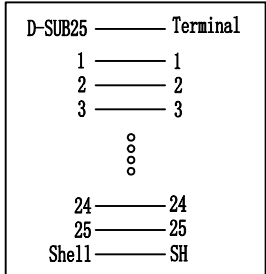

Pin assignment

|                         |          |     |              |             |         |                                 |               |
|-------------------------|----------|-----|--------------|-------------|---------|---------------------------------|---------------|
| 制作                      | Hero. Xu | 日期  | 2024. 10. 30 | 名称          | 端子台     | 型号                              | DB25-G6 (双公头) |
| 审核                      |          |     |              | 版本          | Ver:1.0 | 客户编号                            |               |
| 核准                      |          |     |              | 摄影角度        | 摄影比例    | 第 1 张 共 1 张                     |               |
| 未注线性公差GB1804-m级 (单位:mm) |          |     |              | 角度公差 ±1.5 ° |         | 中山市肯博电子科技有限公司<br>www.kingpow.cn |               |
| 尺寸                      | ≤3       | 3-6 | 6-30         | 30-120      | 120-400 | 400-1000                        | 1000-2000     |
| 公差                      | 0.5      | 1   | 2            | 3           | 5       | 8                               | 10            |