


Operation: 2.0-B Universal Serial Bus Connectors

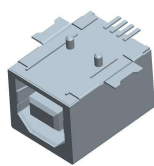

LTEM NO.:USB-B01S 侧贴式

(L16.0×W7.1×H10.9mm -USB-CONNECTORS)



Technical parameter

PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		25mA, 24V DC	
	Initial Contact Resistance		30mΩ max.	50mΩ max.
	Insulation Resistance		100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage		500V AC for 1 minute	350 V AC for 1 minut
Durable Performance	There No Load		6,000 Cycles	5,000 Cycles
	Rated Load		5,000 Cycles	4,000 Cycles
Storage temp.			-25℃~~+75℃(Operating Temp:)	

卧式贴装 SMT

 



侧向导入 LATERAL


精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

Unit:mm

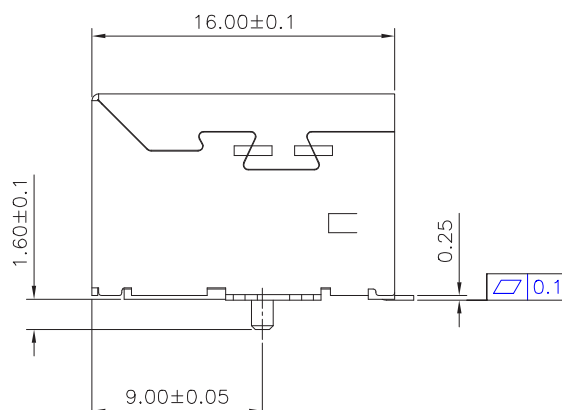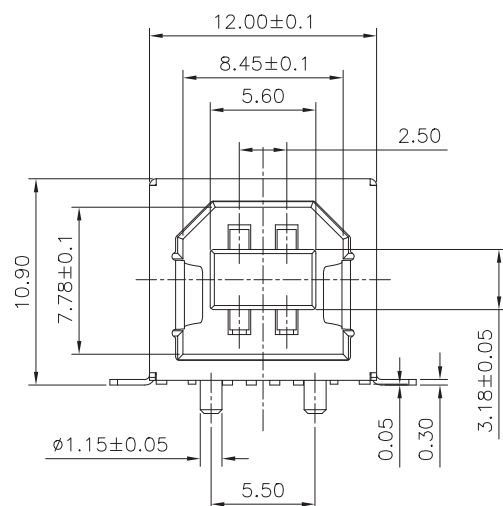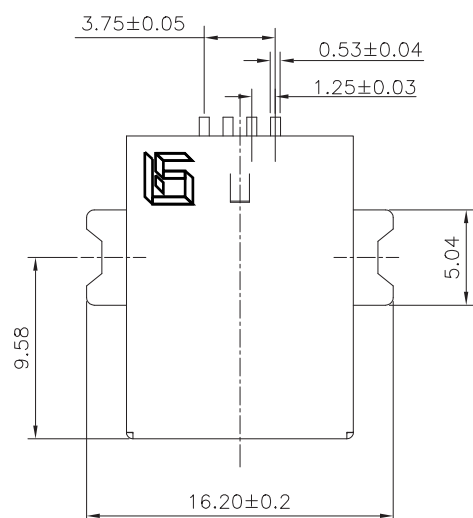

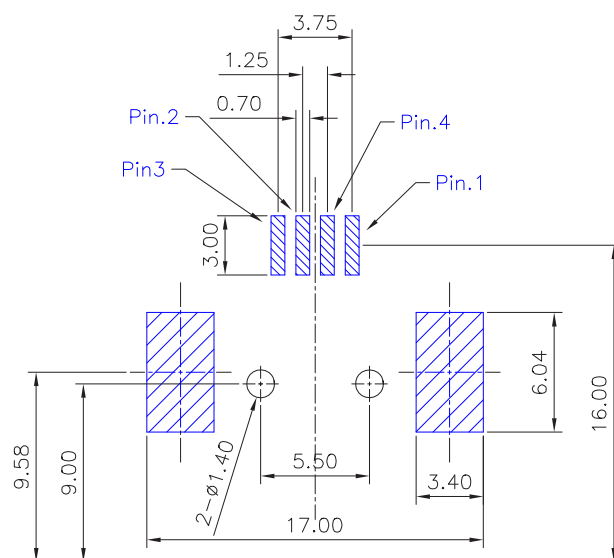

Material declaration

No.	NAME	Type	Description
① A	胶芯	1	PA9T 耐热尼龙 [Black/White]
② B	接触端子	4	磷铜 C5191 [镀金 1u" / 焊区雾锡] t=0. 25
③ C	外壳	1	黄铜 C2680/SPCC [镀镍 50u" min] t=0. 30



本品不屬於危害性廢棄物,須丟棄時可以委託回收商予以回收再生處理。

- Products do not belong to

注記 NOTICE

1. 碩方公司擁有最終解釋權；The company reserves the right of final interpretation;

運送時本產品不要直接與水、酸鹼性化學物質接觸,或放置於含有以上氣體環境中,並且需要注意會有滑落、側翻的危險發生;運輸過程中不能有碰撞或者擠壓,須保證溫度與濕度適中[常溫 25℃,濕度在 50℃以內],不可導致材料變形或氧化。