

SLIDE SWITCH

碩方精密電子開關

 www.Sofng.com

Operation:DIP/卧式 小型 3PIN 二挡 滑动开关 [柄长可定制]

RoHS Compliant

ITEM NO.:MS-1260-□ (Series)

(L6.70mm×W2.75mm×H1.40mm SLIDE-SWITCH)

表面插装 DIP

側向操作 LATERAL

精密部品 NICETY


可靠 STABILIZE

適合環保 RoHS





Technical parameter

LEVEL		A[better product]	B[average product]
PROJECT			
Electrical Properties	Contact Rating	0.3A, 30V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage	300V AC for 1 minute	250 V AC for 1 minut
	There No Load	15,000 Cycles	10,000 Cycles
	Rated Load	12,000 Cycles	8,500 Cycles
	Storage temp.	-25℃~+75℃(Operating Temp:)	
	Operating Force	1.6N. (1N.=100gram-force) ±0.5N	
	Heat Rrsistance	IR Reflow:255℃,5sec. Manual:350℃,3sec.	

CIRCUIT DIAGRAM

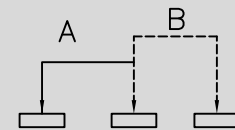

Unit:mm

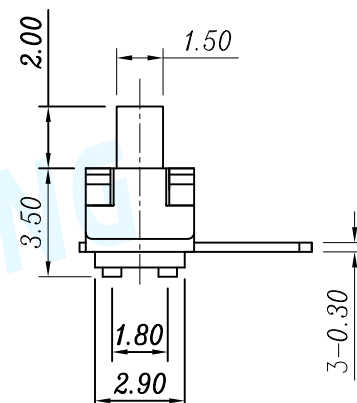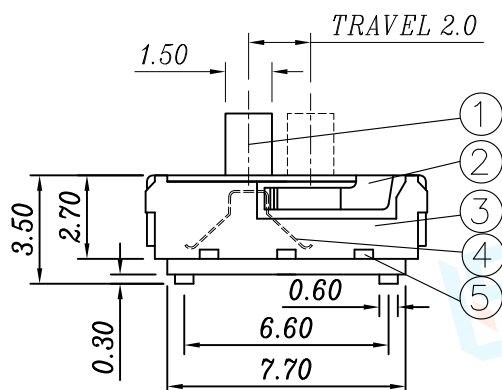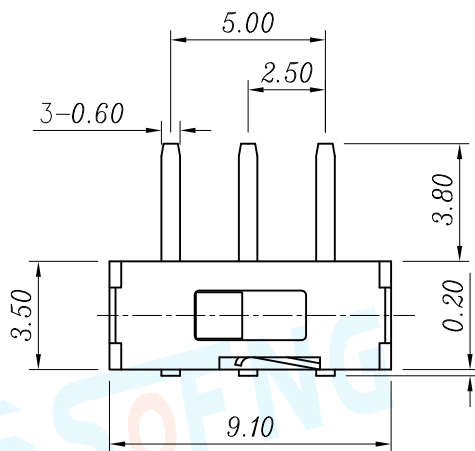 

DECIMALS		ANGLES	
.X	:±0.25	X.°	:±1.5°
.XX	:±0.15	X.X°	:±1.0°
.XXX	:±0.10	.XXX°	:±0.5°