

Operation:DIP/直立式 导边双层(二合一)2.0USB 连接器 (Type-A)



LTEM NO.:USB-327 (Series)

(L14.2×W13.2×H16.9 2.0-USB-CONNECTORS)

表面插装 DIP

正向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

 


Technical parameter

		LEVEL			
PROJECT		A[better product]		B[average product]	
Electrical Properties	Contact Rating	0.25A, 24V DC			
	Initial Contact Resistance	50mΩ max.			
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC		
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut		
	There No Load	6,000 Cycles	5,000 Cycles		
	Rated Load	5,000 Cycles	4,000 Cycles		
	Storage temp.	-35℃～+75℃(Operating Temp:)			
Operating Force		IF:35N MAX. (EF:10.0N MIN.)			
Heat Rrsistance		IR Ref low:235℃, 5sec. Manual:350℃, 3sec.			

PIN SIGNAL

1/5	VCC	+5V
2/6	-DATA 0	Neagative Data Channel 0
3/7	+DATA 0	Positive Data Channel 0
4/8	GND	Ground

Unit:mm

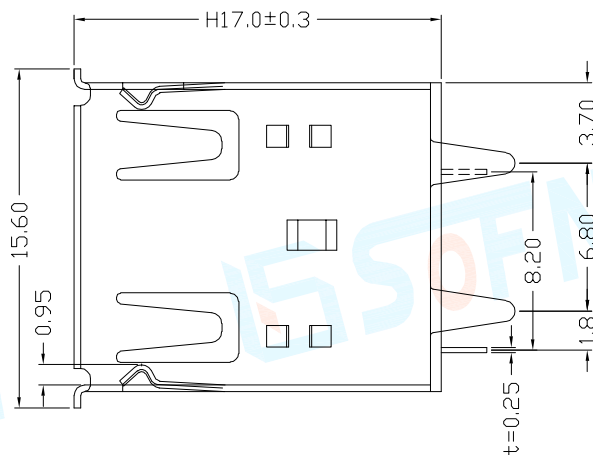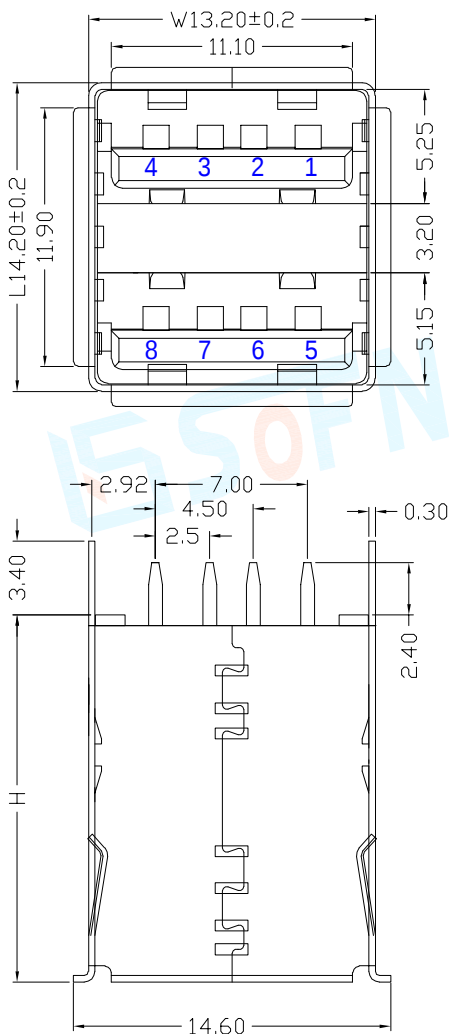

P.C.B LAYOUT

