

SLIDE SWITCH



碩方精密電子開關

www.Sofn.com

Operation: SMT/贴片卧式 小型 4PIN 二档位 滑动开关 [柄长可定制]



LTEM NO.: MS-1385 (Series)

(L11.25mm × W3.6mm × H2.2mm SLIDE-SWITCH)

表面贴装 SMT

側向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE


適合環保 RoHS

Technical parameter


PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	0.5A, 12V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	300V AC for 1 minute	250 V AC for 1 minut
	There No Load	15,000 Cycles	10,000 Cycles
Durable Performance	Rated Load	12,000 Cycles	8,500 Cycles
	Storage temp.	-25℃~+75℃(Operating Temp:)	
	Operating Force	1.8N. (1N.=100gram-force) ±0.5N	
	Heat Rrsistance	IR Reflow:255℃,5sec. Manual:350℃,3sec.	

Material declaration		
No.	NAME	Description
A	拨柄	PA46 耐热尼龙塑料
B	基座	LCP 30%G/F (Black)耐热塑胶
C	盖板	C5191R-H 磷铜[镀银]
D	弹片	Beryllium bronze 铍青铜[单面镀银]
E	弹簧	不锈钢 SUS304 t=0.2mm
F	嵌件	C5191R-H 磷铜[镀银]

CIRCUIT DIAGRAM

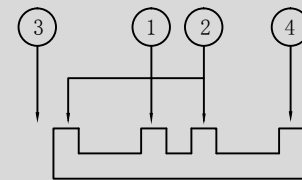

Unit:mm

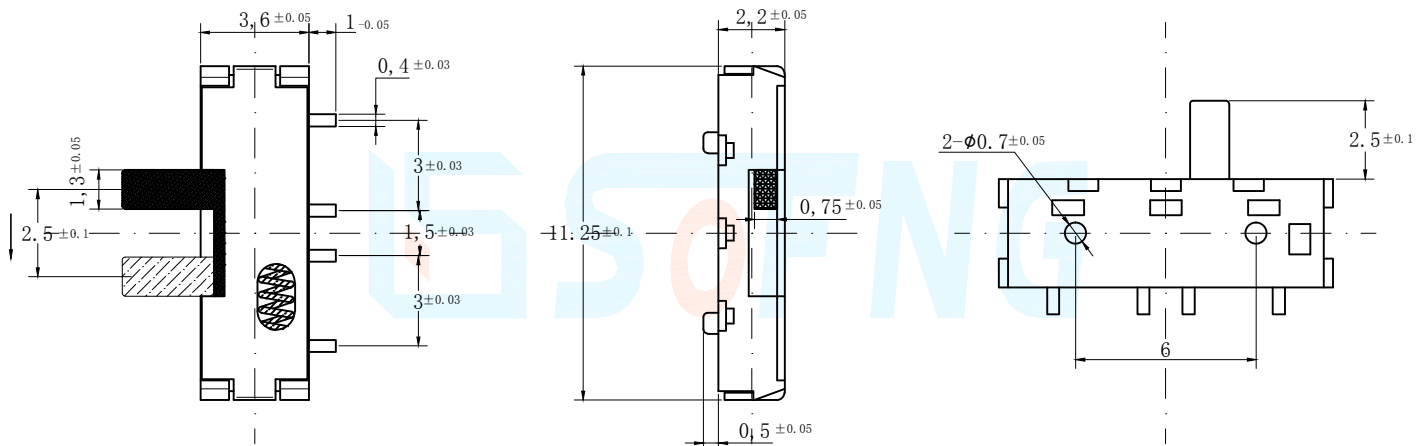

P.C.B LAYOUT

