

# Adapter Han RJ45 module / RJ45 plug

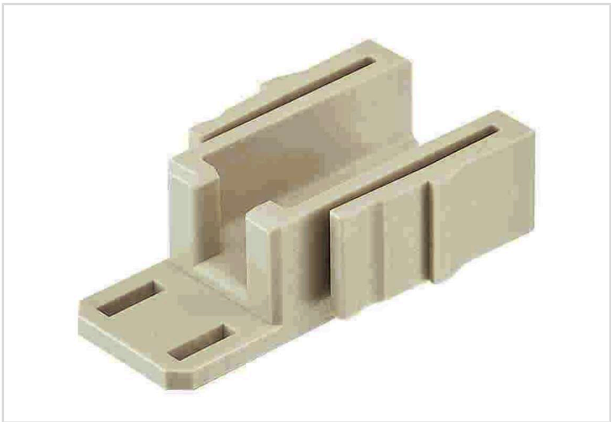


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 000 9967
Specification	Adapter Han RJ45 module / RJ45 plug
HARTING eCatalogue	<a href="https://b2b.harting.com/09140009967">https://b2b.harting.com/09140009967</a>

## Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® RJ45 module
Size of the module	Single module
Description of the module	Adapter

## Version

Gender	Male
--------	------

## Technical characteristics

Rated current	1 A
Rated voltage	50 V
Rated impulse voltage	0.8 kV
Pollution degree	3
Rated voltage acc. to UL	30 V
Insulation resistance	>10 <sup>10</sup> Ω
Limiting temperature	-40 ... +70 °C
Mating cycles	≥500

## Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0



**Pushing Performance**  
Since 1945

## Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

## Specifications and approvals

Specifications	IEC 60664-1
	IEC 61984
Approvals	DNV GL

## Commercial data

Packaging size	2
Net weight	6 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140018877
ETIM	EC002312
eCl@ss	27440207 Adapter for industrial connectors (module/contact insert)