



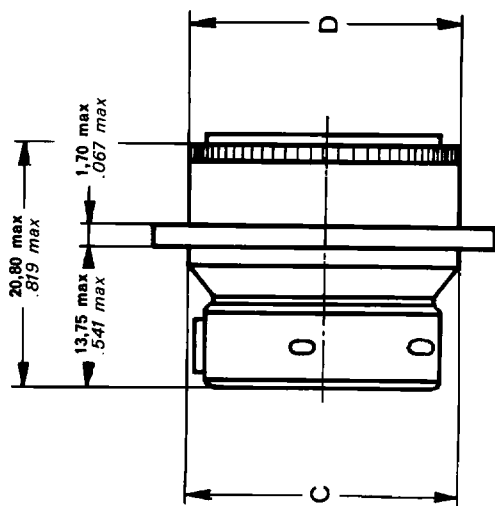

RSM 00

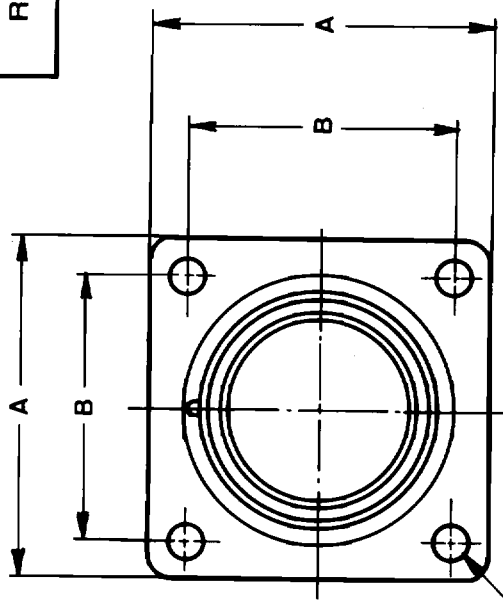

N° du FABR. MANUF. N° HERST. N°	RÉFÉRENCE PART No BEZEICHNUNG	A max.		B max.		C max.		D max.	
		inches	mm.	inches	mm.	inches	mm.	inches	mm.
9	RSM 00- 3-**-P/S	.880	22,35	.625	15,87	.567	14,40	.611	15,50
9	RSM 00- 7-**-P/S	1.004	25,50	.719	18,26	.670	17,25	.697	17,70
9	RSM 00-12-**-P/S	1.039	27,90	.812	20,63	.817	20,75	.821	20,85
9	RSM 00-19-**-P/S	1.193	30,30	.906	23,01	.942	23,90	.947	24,05
9	RSM 00-27-**-P/S	1.286	32,65	.968	24,59	1.125	28,55	1.031	27,45

COMPAGNIE DEUTSCH

PARTIE FIXE A COLLERETTE CARRÉE
VERROUILLAGE PUSH PULL

RECEPTACLE SQUARE FLANGE MTG.
PUSH PULL QUICK DISCONNECT
CONNECTOR

STECKDOSE MIT VIERECKIGEM
BEFESTIGUNGSFLANSCH
KUGELSCHNELLVERSCHLUSS (PUSH - PULL)



RSM 00

1. Pour les brochages et les positionnements des isolants voir pages 10 à 12.
NOTE.

1. For contact arrangements and alternate insert positions see pages 10 to 12.
NOTE.

1. Kontaktnordnungen und Winkelstellungen siehe Seite 10 bis 12.
ANMERKUNG.