

# Han 10M-Metal Cover-Bolt-for Base

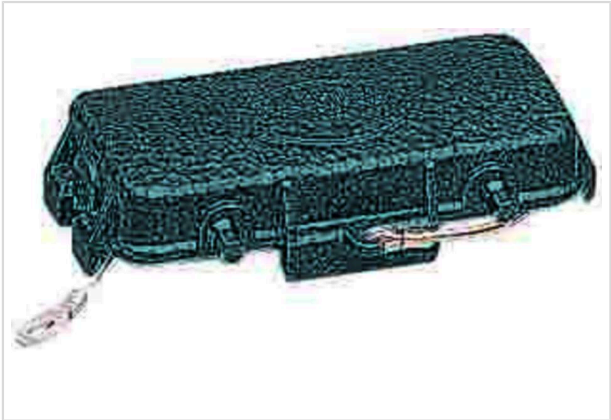


Image is for illustration purposes only. Please refer to product description.

Part number	09 37 010 5405
Specification	Han 10M-Metal Cover-Bolt-for Base
HARTING eCatalogue	<a href="https://b2b.harting.com/09370105405">https://b2b.harting.com/09370105405</a>

## Identification

Category	Accessories
Series of hoods/housings	Han® M
Type of accessory	Protection cover
Description of the accessory	for bulkhead mounted housings
	for surface mounted housings
	for cable to cable housing
	Metal
	With fixing cord

## Version

Size	10 B
Locking type	Double locking lever

## Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

## Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R1 (HL 1-3) R7 (HL 1-3)

## Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	DNV GL

## Commercial data

Packaging size	1
Net weight	5 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140055551
ETIM	EC002314
eCl@ss	27440208 Cap for industrial connectors