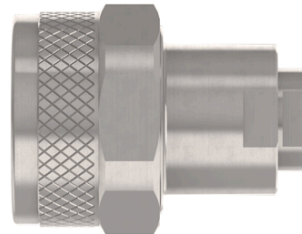


COAXIAL CONNECTOR, N, 50 Ohm, Straight cable plug (male)

11_N-50-3-44/113_N

Properties

- Screwed coupling mechanism for sturdy and reliable connection
- IP rating (interface, mated) IP67
- Interface dimensions according IEC/MIL

**Product configuration**

Interface type	Gender	Standard
N	plug	IEC 61169-16_MIL-STD-348A/304_CECC 22210

Interface and material data

Piece parts	Material	Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer conductor	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	
Coupling nut	Brass	SUCOPLATE (R) Plating
Gasket	VMQ (Silicone rubber)	

Electrical data

Impedance	50 Ω
Interface frequency	18 GHz

Mechanical data

Weight	0.0298 kg
Mating cycles	500
Cable entry centre contact	soldered
Cable entry outer contact	soldered

Environmental data

Operation temperature	-65 °C ... 165 °C
-----------------------	-------------------

COAXIAL CONNECTOR, N, 50 Ohm, Straight cable plug (male)
11_N-50-3-44/113_N

Suitable cables	
Cable group	Y5 - 3 mm / 50 Ohm
	Y17 - 3 mm / 50 Ohm
	Y12 - 3 mm / 50 Ohm
Additional Information	
Only as assembly	No

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/ EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P3591 / Date of publication: 25.11.2023 / uncontrolled copy