

Illuminated pushbutton Ø 22 mm silver contact

82-6551.1133



<https://eao.com/p/82-6551.1133>

Your product:



82-6551.1133

Illuminated pushbutton Ø
22 mm silver contact

FRONT

Front bezel material:	Aluminium
Front bezel shape:	flush
Front form:	round
Front dimension:	Ø 25 mm

MOUNTING

Mounting cut-out:	Ø 22 mm
Mounting type:	Panel mounting

OPERATING-/INDICATION PART

Illumination colour:	Green
Lens material:	Aluminium
Lens illumination:	illuminative
Lens optics:	opaque
Shape of illumination:	Ring
Lens shape:	flush
Lens colour:	Nature

ELECTRICAL CHARACTERISTICS

Operating voltage:	12 V AC/DC
Rated Operational Voltage U _e :	250 VAC
Pollution degree:	2, according to EN IEC 60947-1

Contacts:	1 C		
Thermal current I_{th}:	5 A		
Switching voltage and switching current:	according to IEC 60947-5-1 (Silver contacts) Service categorie AC-15 Voltage 24 VAC 35 VAC 110 VAC 220 VAC Switch rating DC service categorie DC-13 (Silver contacts) Voltage 24 VDC 35 VDC 110 VDC 220 VDC		Current 1 A 1 A (M12 versio 1 A 0.5 A Current 0.7 A 0.5 A (M12 vers 0.2 A 0.1 A

according to UL 508 (Silver contacts) $\cos\phi$ 0,75 ... 0,8 Voltage 120 VAC 240 VAC 24 VAC	Current 5 A 3 A 1 A
---	------------------------------

Electric strength:	1500 VAC, 50 Hz 1 minute between life terminals and ground
Operation current:	7 mA
Rated insulation voltage U_i:	250 V
Electrical lifetime:	50 000 cycles of operation

MECHANICAL CHARACTERISTIC

Operating Travel:	ca. 3 mm
Mechanical lifetime:	1 Mio. cycles of operation
Terminal:	Soldering terminal, 2.8 x 0.5 mm
Weight:	0.018 kg
Contact material:	Silver
Tightening torque:	0.5 ... 0.6 Nm
Switching system:	Snap-action switching element
Operating force:	4 N ... 7 N
Switching action:	Momentary

AMBIENT CONDITION

Shock resistance:	Max. 500 m / s ² as per IEC 60068-2-27
Operating temperature:	– 30 °C ... + 70 °C
Climate resistance:	

Damp heat, 21 days according to IEC 60512-11

Storage temperature: - 40 °C ... + 80 °C

Vibration resistance: 10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6

IP front protection: IP65, IP67

CERTIFICATE

Approbations: CB, CCC, C UL, UL

Conformities: CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

RoHS: RoHS compliant


REACH: REACH compliant

OTHER

Short Description: Illuminated pushbutton Ø 22 mm silver contact, Momentary, 12 V AC/DC, 1 C, Soldering terminal, 2.8 x 0.5 mm, round, Aluminium, Green, Nature


Kind of illumination: Single-LED

Dimension drawings:

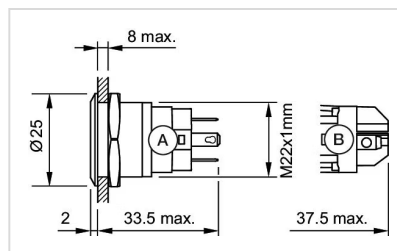

A = Solder terminal
B = Screw terminal

Mounting cut-outs:

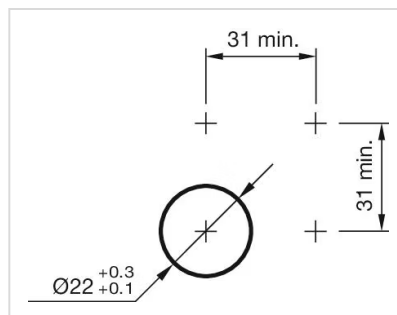

Component layouts:



Wiring diagrams:

