

Illuminated pushbutton Ø 16 mm silver contact

82-4152.2114



<https://eao.com/p/82-4152.2114>

Your product:



82-4152.2114

Illuminated pushbutton Ø
16 mm silver contact

FRONT

Front bezel shape:	flush
Front dimension:	Ø 18 mm
Front bezel material:	Stainless steel
Front form:	round

MOUNTING

Mounting type:	Panel mounting
Mounting cut-out:	Ø 16 mm

OPERATING-/INDICATION PART

Lens colour:	Silver
Lens optics:	opaque
Illumination colour:	Red
Lens illumination:	illuminative
Lens shape:	flush
Shape of illumination:	Ring
Lens material:	Stainless steel

ELECTRICAL CHARACTERISTICS

Contacts:	1 C
Switching voltage and switching current:	

according to IEC 60947-5-1 (Silver contacts)	
Service categorie AC-15	
Voltage	Current
24 VAC	1 A
35 VAC	1 A (M12 version)
110 VAC	1 A
220 VAC	0.5 A
Switch rating DC service categorie DC-13 (Silver contacts)	
Voltage	Current
24 VDC	0.7 A
35 VDC	0.5 A (M12 version)
110 VDC	0.2 A
220 VDC	0.1 A

according to UL 508 (Silver contacts)	
cosφ 0,75 ... 0,8	
Voltage	Current
120 VAC	5 A
240 VAC	3 A
24 VAC	1 A

Pollution degree:	2, according to EN IEC 60947-1
Electrical lifetime:	50 000 cycles of operation
Operating voltage:	24 V AC/DC
Rated insulation voltage Ui:	250 V
Operation current:	7 mA
Electric strength:	1500 VAC, 50 Hz 1 minute between life terminals and ground
Rated Operational Voltage Ue:	250 VAC
Thermal current Ith:	5 A

MECHANICAL CHARATERISTIC

Operating Travel:	ca. 3 mm
Weight:	0.018 kg
Switching system:	Snap-action switching element
Switching action:	Maintained
Tightening torque:	0.5 ... 0.6 Nm, Screw terminal 0.1 Nm
Operating force:	4 N ... 7 N
Mechanical lifetime:	500 000 cycles of operation
Terminal:	Screw terminal
Contact material:	Silver

AMBIENT CONDITION

Operating temperature:	
-------------------------------	--

– 30 °C ... + 70 °C

Shock resistance:

Max. 500 m / s² as per IEC 60068-2-27

IP front protection:

IP65, IP67

Climate resistance:

Damp heat, 21 days according to IEC 60512-11

Storage temperature:

– 40 °C ... + 80 °C

Vibration resistance:

10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6

CERTIFICATE

Conformities:

CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

Approbations:

CB, CCC, C UL, UL

RoHS:

RoHS compliant

REACH:

REACH compliant

OTHER


Kind of illumination:

Single-LED


Short Description:

Illuminated pushbutton Ø 16 mm silver contact, Maintained, 24 V AC/DC, 1 C, Screw terminal, round, Stainless steel, Red, Silver


Wiring diagrams:

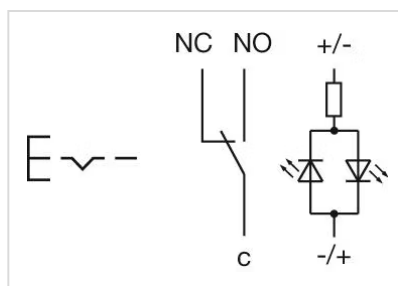

Mounting cut-outs:

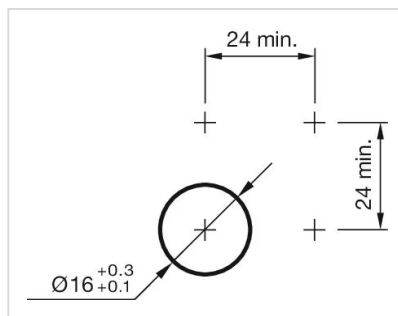

Dimension drawings:

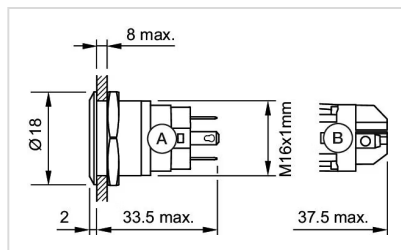

A = Solder terminal
B = Screw terminal

Component layouts:

