

Pushbutton Ø 22 mm silver contact

82-6162.1000.B002



<https://eao.com/p/82-6162.1000.B002>

Your product:



82-6162.1000.B002
Pushbutton Ø 22 mm silver contact

FRONT

Front dimension:	Ø 25 mm
Front bezel shape:	flush
Front bezel material:	Stainless steel
Front form:	round

MOUNTING

Mounting cut-out:	Ø 22 mm
Mounting type:	Panel mounting

OPERATING-/INDICATION PART

Lens material:	Stainless steel
Lens shape:	flush
Lens colour:	Silver
Lens optics:	opaque
Symbol:	Standby
Lens illumination:	non illuminative

ELECTRICAL CHARACTERISTICS

Thermal current I_{th}:	5 A
Rated Operational Voltage U_e:	250 VAC
Electrical lifetime:	50 000 cycles of operation
Electric strength:	1500 VAC, 50 Hz 1 minute between life terminals and ground

Pollution degree:	2, according to EN IEC 60947-1
Switching voltage and switching current:	according to IEC 60947-5-1 (Silver contacts) Service categorie AC-15
Voltage	Current
24 VAC	1 A
35 VAC	1 A (M12 versio
110 VAC	1 A
220 VAC	0.5 A
Switch rating DC service categorie DC-13 (Silver contacts)	
Voltage	Current
24 VDC	0.7 A
35 VDC	0.5 A (M12 vers
110 VDC	0.2 A
220 VDC	0.1 A
according to UL 508 (Silver contacts)	
$\cos\phi$ 0,75 ... 0,8	
Voltage	Current
120 VAC	5 A
240 VAC	3 A
24 VAC	1 A
Contacts:	1 C
Rated insulation voltage Ui:	250 V

MECHANICAL CHARACTERISTIC

Switching system:	Snap-action switching element
Contact material:	Silver
Operating force:	4 N ... 7 N
Weight:	0.02 kg
Tightening torque:	0.5 ... 0.6 Nm, Screw terminal 0.1 Nm
Terminal:	Screw terminal
Switching action:	Momentary
Mechanical lifetime:	1 Mio. cycles of operation
Operating Travel:	ca. 3 mm

AMBIENT CONDITION

Storage temperature:	– 40 °C ... + 80 °C
Operating temperature:	– 30 °C ... + 70 °C
Climate resistance:	Damp heat, 21 days according to IEC 60512-11
IP front protection:	IP65, IP67
Vibration resistance:	10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6
Shock resistance:	100 g according to IEC 60068-2-27

Max. 500 m / s² as per IEC 60068-2-27

CERTIFICATE

REACH: REACH compliant

Conformities: CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)


RoHS: RoHS compliant

Approbations: CB, CCC, C UL, UL


OTHER

Short Description: Pushbutton Ø 22 mm silver contact, Momentary, 1 C, Screw terminal, round, Stainless steel, Standby, Silver


Wiring diagrams:

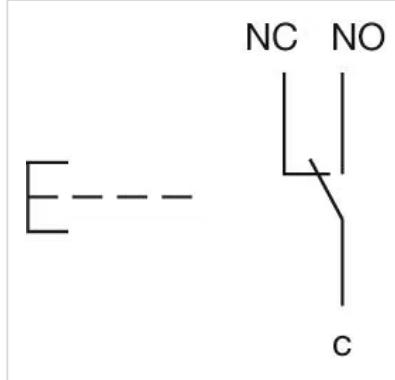

Mounting cut-outs:

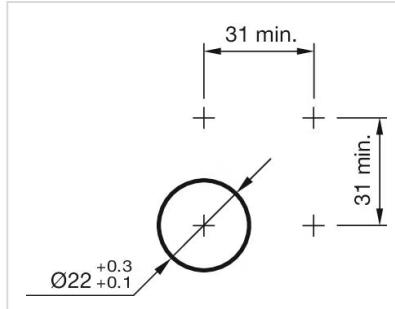

Dimension drawings:

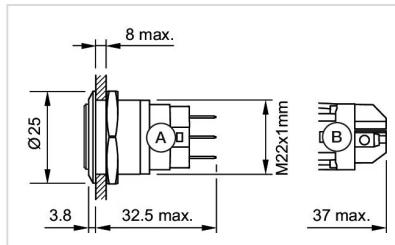

A = Solder terminal
B = Screw terminal

Component layouts:

