


Coaxial Cable Connector 14_BMA-50-3-2/111_N

Description

Straight bulkhead cable plug

Interface standards

IEC 60169-33_MIL-STD-348A/321

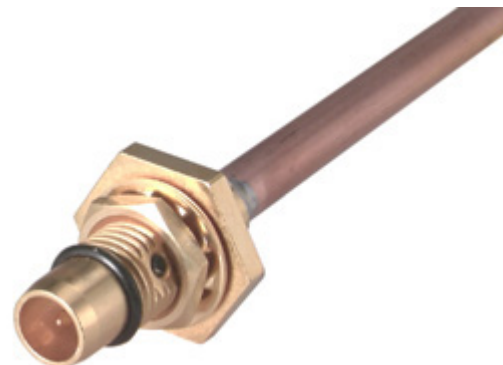

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	18 GHz

Mechanical Data

Centre contact	plugged
Outer contact	soldered
Weight	0.0037 kg

Environmental Data

Operating temperature	-65 °C to 125 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Body	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	
Gasket	NR (Natural Rubber)	
Fastening nut	Brass	Gold Plating
Washer	Bronze	Gold Plating

Related Documents

Outline drawing	DOU-00121036
Catalogue drawing	DCA-00008971
Assembly instruction	DOC-0000180997
Mounting hole	DOU-00008972

Ordering Information

Single package	14_BMA-50-3-2/111_NE
Bulk 100 pcs package	14_BMA-50-3-2/111_NH

Additional Information

Suitable cables	EZ_141_TP_M17
-----------------	---------------