
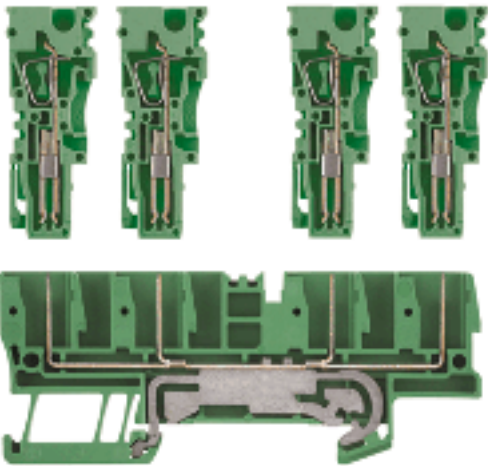
 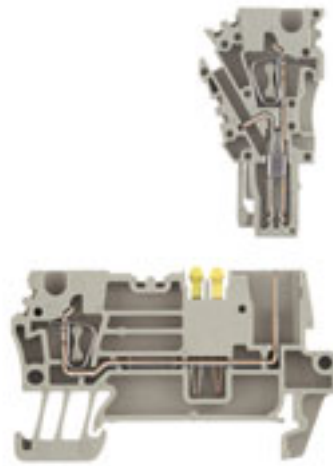




General ordering data

Order No.	1815140000
Part designation	ZTPE 2.5/4AN/4
Version	Earth terminal, 2.5 mm ² , Tension clamp connection, Wemid, green/yellow, TS 35
EAN	4032248370054
Qty.	50 pc(s).

Product notes

Note, technical data	2.5 mm ² - flexible conductors with wire-end ferrules are crimped with the Weidmüller PZ 6/5 crimping tool. UL & CSA D = 600V / 5A
Product description	WeiCoS - plug-in modular terminals for conductor cross-sections 0.13 to 4 mm ² .

Additional technical data

Colour of insulating material	green/yellow
Connection direction	top

Additional technical data

End plate required	Yes
Explosion-tested version "Ex e"	No
Installation advice	TS 35
Insulating material	Wemid
Levels cross-connected internally	No
No. of levels	1
Open sides	right
Operating temperature range	- 50 °C, + 120 °C
Product family	Z-series
Type of connection	Tension clamp connection
Type of mounting	Snap-on
UL 94 flammability rating of insulation material	V-0
Version	PE terminal

Conductors for clamping (additional connection)

Type of connection	Plug-in connection
Solid, min.	0.5 mm ²
Solid, max.	4 mm ²
Flexible, min.	0.5 mm ²
Flexible, max.	4 mm ²
Flexible with ferrule, min. (DIN 46228 pt 1)	0.5 mm ²
Flexible with ferrule, max. (DIN 46228 pt 1)	2.5 mm ²
Flexible, min., ferrule with plastic collar (DIN 46228 pt 4)	0.5 mm ²
Flexible, max., ferrule with plastic collar (DIN 46228 pt 4)	2.5 mm ²

Conductors for clamping (rated connection)

Clamping range, min.	0.13 mm ²
Clamping range, max.	4 mm ²
Type of connection	Tension clamp connection
2nd type of connection	plugged
Connection direction	top
Stripping length	10 mm
Blade size	0.6 x 3.5 mm
Gauge to IEC 60947-1	A2
Solid, min.	0.5 mm ²
Solid, max.	4 mm ²
Flexible, min.	0.5 mm ²
Flexible, max.	4 mm ²
Flexible with ferrule, min. (DIN 46228/1)	0.5 mm ²
Flexible with ferrule, max. (DIN 46228/1)	2.5 mm ²
Flexible, min., ferrule with plastic collar (DIN 46228 pt 4)	0.5 mm ²
Flexible, max., ferrule with plastic collar (DIN 46228 pt 4)	2.5 mm ²
AWG conductor size, min.	AWG 12
AWG conductor size, max.	AWG 26
AWG conductor size, min.	0.13 mm ²
AWG conductor size, max.	3.31 mm ²

Conductors for clamping (rated connection)

Dimensions

Width	5.1 mm
Height of lowest version	35 mm
Length	85.5 mm
TS 35 offset	45.5 mm

Rating data

Rated cross-section	2.5 mm ²
Rated voltage	500 V
Standards	IEC 60947-7-2
Pollution severity	3

Approvals

Approvals institutes



Downloads

STEP	1815140000_34451_ZTPE_2.5-4AN-4_STP.stp
------	---

Classifications

ETIM 2.0	EC000897
ETIM 3.0	EC000897
eClass 4.1	27-14-03-05
eClass 5.0	27-14-03-05
eClass 5.1	27-14-03-05

Similar products

Order No.	Part designation	Version
1815080000	ZTPE 2.5/2AN/1	Earth terminal, 2.5 mm ² , Tension clamp connection, Wemid, green/yellow, TS 35
1815100000	ZTPE 2.5/3AN/1	Earth terminal, 2.5 mm ² , Tension clamp connection, Wemid, green/yellow, TS 35
1815120000	ZTPE 2.5/4AN/2	Earth terminal, 2.5 mm ² , Tension clamp connection, Wemid, green/yellow, TS 35