

## Han E Crimp Contact - M - 20 AWG Fe(Au)

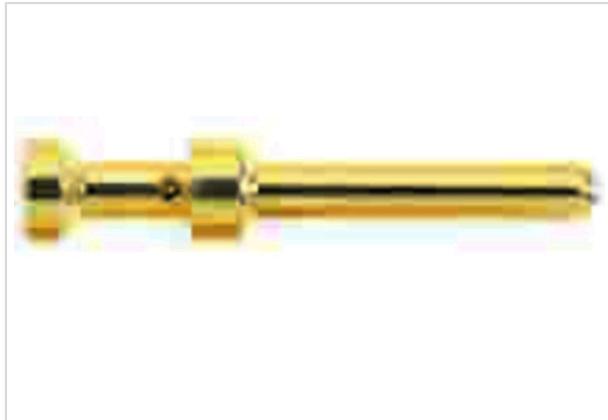


Image is for illustration purposes only. Please refer to product description.

Part number	09 33 000 6172
Specification	Han E Crimp Contact - M - 20 AWG Fe(Au)
HARTING eCatalogue	<a href="https://b2b.harting.com/09330006172">https://b2b.harting.com/09330006172</a>

### Identification

Category	Contacts
Series	Han E®
Type of contact	Crimp contact

### Version

Gender	Male
Contact identification	acc. to IEC 60584 type J
Manufacturing process	Turned contacts

### Technical characteristics

Conductor cross-section	0.5 mm²
Conductor cross-section	AWG 20
Rated current	≤16 A
Contact resistance	≤1 mΩ
Stripping length	7.5 mm

### Material properties

Material (contacts)	Iron
Surface (contacts)	Gold plated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained

## Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
----------------	--------------------------

## Commercial data

Packaging size	25
Net weight	1.17 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140049871
ETIM	EC000796
eCl@ss	27440204 Contact for industrial connectors