


PXM6012/03S/ST Datasheet

Product Name // Front Panel Mount Connector PXM6012
Series 3 Contact Socket Screw Termination (contacts supplied fitted) Metal Body

 [View Product Page](#)

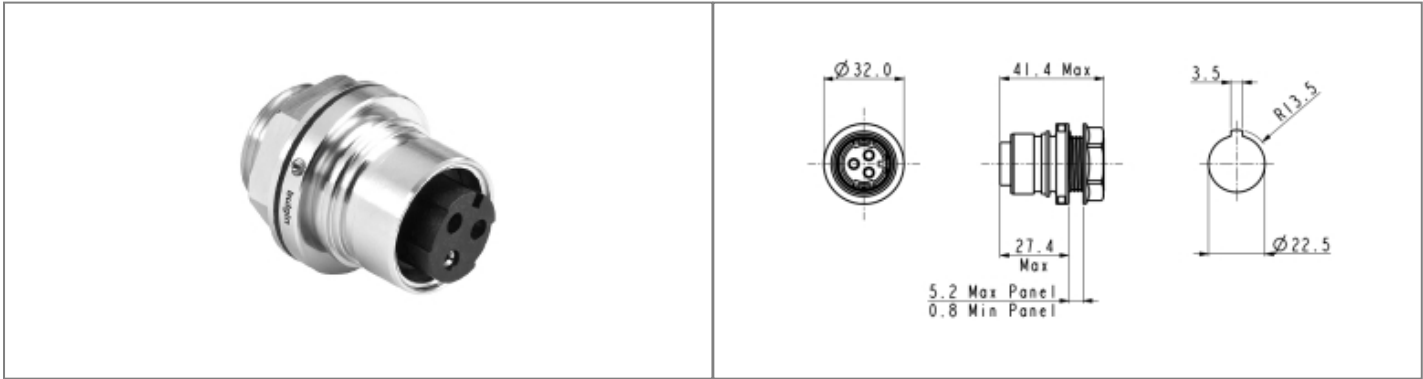

// Product Description:

- | | |
|---|---|
| <ul style="list-style-type: none">Front Panel Mount ConnectorsWater and dustproof to IP66, IP68, IP69K when mated with compatible connector30 degree push twist locking, tamperproof lock prevents accidental un-matingSocket3 Contacts | <ul style="list-style-type: none">Screw contacts supplied fittedMetal BodyPXM6083 Sealing Cap available separately to maintain IP rating of unmated connectorsMate with PXM6010 Series Flex Connectors |
|---|---|

// General Information:

Product Display Title:	Front Panel Mount Connectors
Product Family:	Circular Power Connectors
Product Series:	6000 Series Buccaneer
Approvals:	cUL, UL, VDE
Body Colour:	Metallic Grey
Body Material:	Brass
Body Material Type:	Metal Body
Contact Type:	Socket Contact
Coupling Type:	Push-Twist
Current Max:	16A, 11A
Diameter Over Coupling Ring Mm:	32mm
Function:	Front Panel Mount Connector
Insulation Resistance:	>10 ⁶ MΩ @500V DC
Ip Rating:	IP66, IP68, IP69K
Max Contact Accomodation Awg:	14AWG
Min Contact Accomodation Awg:	14AWG
Max Contact Accomodation Mm2:	0.52mm2
Min Contact Accomodation Mm2:	0.52mm2
Max Operating Temperature:	+120°C
Min Operating Temperature:	-40°C
Max Panel Thickness:	5.2mm
Min Panel Thickness:	0.8mm
Number Of Contacts:	3 Contacts
Panel Cut Out:	22.50xR13.5-3.5mm
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	EN60068-2-11 Test Ka Salt Mist
Thread Size:	M22x1.5-6g
Voltage Max:	277V

// Product PDF Links

-  [6000 Series power connectors...](#)
-  [6000 Series metal body power...](#)

// Product 3D CAD Model Links

-  [PXM6012/03S/ST3D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)