


PXMBNI08FPF08AFLM11002 Datasheet

Product Name // PXMBNI08FPF08AFLM11002

 [View Product Page](#)

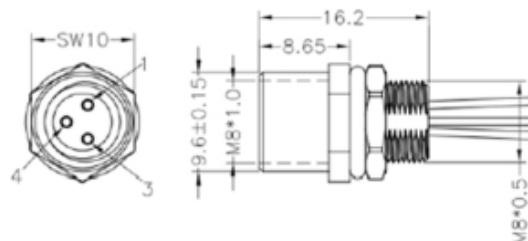

// Product Description:

- | | |
|---------------------------|---|
| ⬢ Material=Metal | ⬢ Operating Temperature= -25°C to +85°C |
| ⬢ Pins=4 | ⬢ Contact Resistance=5? |
| ⬢ Max Rating=60Vac | ⬢ Insulation Resistance=>100M? |
| ⬢ Ingress Protection=IP67 | ⬢ Mechanical Cycles=100 (min) |

// General Information:

Product Display Title:	M8 Series Front Panel Mount Connectors
Product Family:	Circular Automation Connectors
Product Series:	M8 Series
Body Material:	Brass - Nickel Plated
Contact Type:	Socket Contact
Number Of Contacts:	8 Contacts

// Product PDF Links



M8 Series automation connectors...

// Product 3D CAD Model Links



PXMBNI08FPF08AFLM110023D CAD Model



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)